


Data sheet | Item number: 756-5402/060-010



Sensor/actuator cable; fitted on both ends; 5-pole; M12 socket, straight;  
M12 plug, angled; 1 m



756-5402/060-010

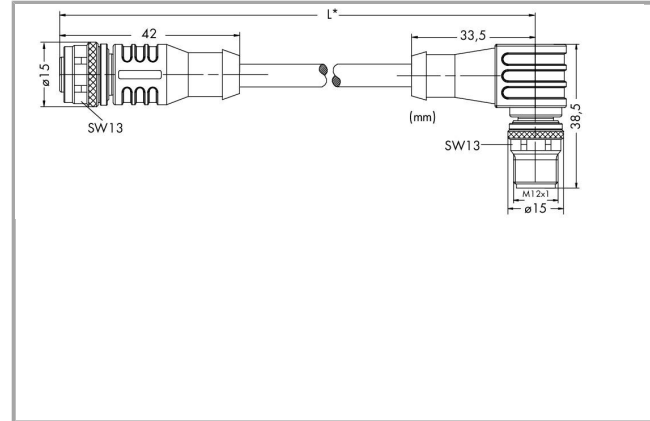

RoHS  Compliant [BOMcheck.net](https://www.bomcheck.net)

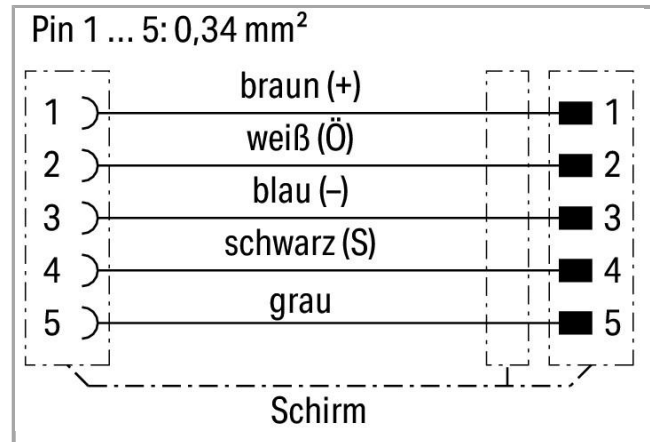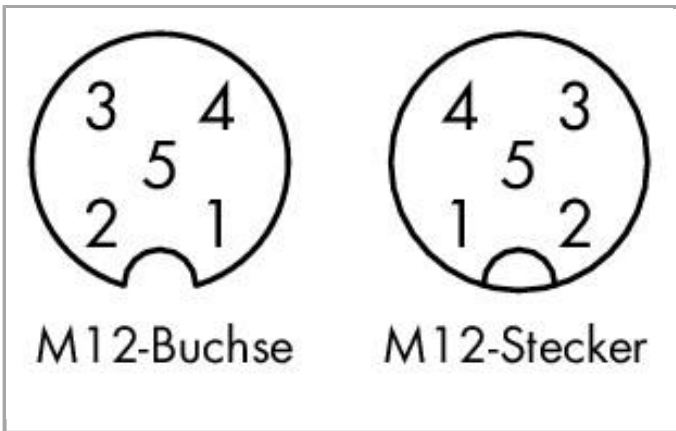

Item description

Short description:

- PUR, halogen-free
- Suitable for drag chains
- Good resistance to microbes, hydrolysis, oil, chemicals and UV radiation.
- Good chemical resistance.
- Cable used: UL listed



## Data

### Technical Data

Connection type	M12 socket - M12 plug
No. of poles	5
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	0°
Leitungsanschlussrichtung zur Steckrichtung (2)	90°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded
Steckgesichtskodierung Leitung/Adapter 2 1	A coded
Cable length	1 m
Operating voltage	AC/DC 250 V
Operating current	4 A
Rated surge voltage	1,5 kV

### Mechanical data

Bending cycles	2 Mio.
Schleppkettentauglichkeit	yes
Color of sheathed cable	black
Durchmesser der Mantelleitung	6.3 ... 6.7 mm
Sheath material	Polyurethane (OPUR), halogen-free per DIN VDE 0472 Part 815, flame resistant per IEC 332-2, self-extinguishing
Halogen-free	Yes
Housing material	Polyurethan (PUR)
Contact material	CuSn
Contact plating	CuNi/Au
Tightening torque	1 Nm
Weight	45 g

### Environmental Requirements

Umgebungstemperatur (Betrieb) bewegt	-25 ... +90 °C
Umgebungstemperatur (Betrieb) ruhend	-50 ... +90 °C
Protection class	IP67
Degree of pollution (5)	3 acc. to VDE 0110

### Commercial data

Country of origin	HU
GTIN	4045454724627
Customs Tariff No.	85444290900



Downloads

**Documentation**

System Description

IP67 Cables and Pluggable Connectors

pdf  
293.9 kB

Download

---

Subject to changes.

---