





RoHS 
Compliant

[BOMcheck.net](https://www.bomcheck.net)

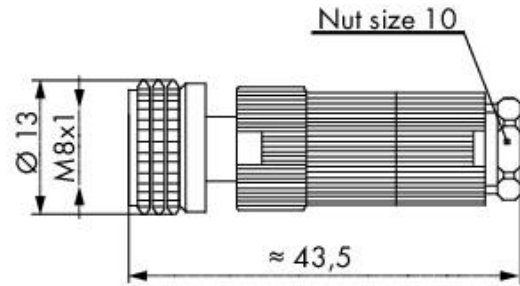

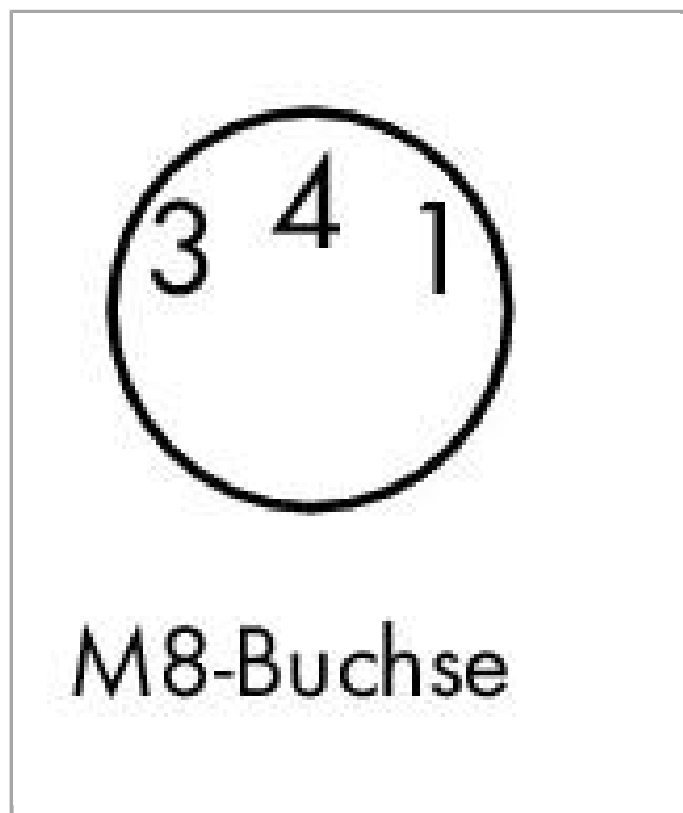

Conductor sizes
Ø 4 ... 5 mm/0.14 ... 0.34 mm²

Data

Technical Data

Connection type	M8 socket
No. of poles	3
Leistungsanschlussrichtung zur Steckrichtung	0°

Connection data

Connection type (1)	Eindringtechnik
---------------------	-----------------

Mechanical data

Connectable sheathed cable diameter	4 ... 5 mm
Weight	13 g

Environmental Requirements

Protection class	IP67
------------------	------

Commercial data

Country of origin	DE
GTIN	4045454983321
Customs Tariff No.	85444290900



Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors	pdf 293.9 kB	Download
--------------------------------------	-----------------	----------

Subject to changes.
