



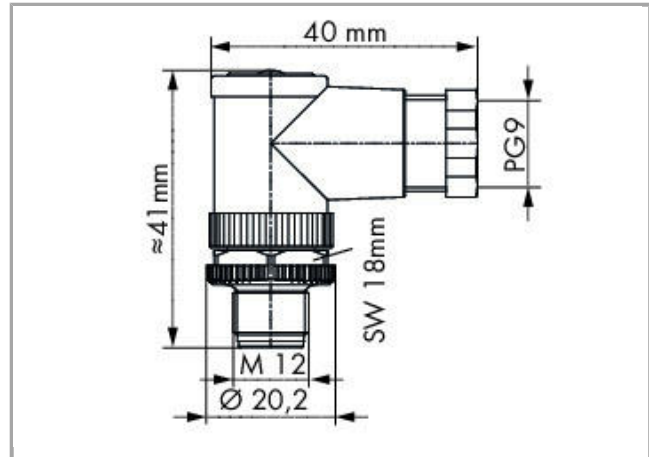

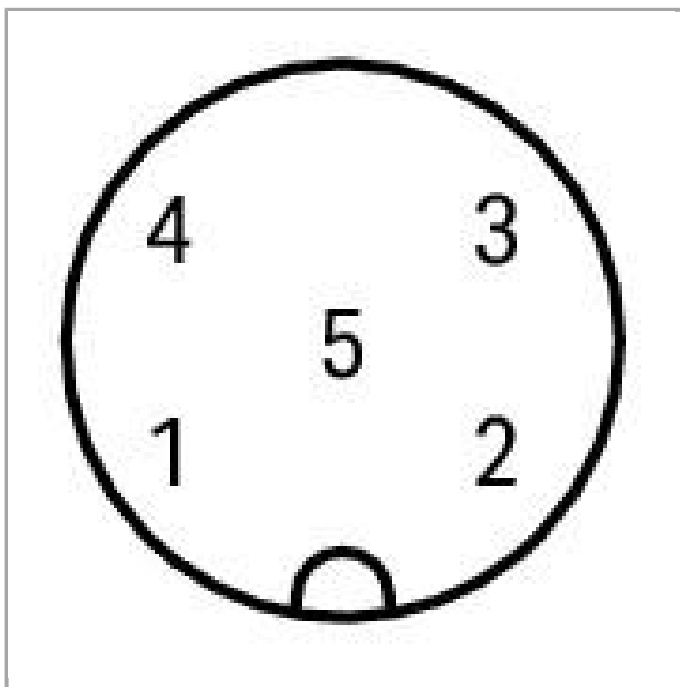

Conductor size

Ø 6 ... 8 mm / 0.14 - 0.5 mm<sup>2</sup>

## Data

### Technical Data

|                                             |          |
|---------------------------------------------|----------|
| Connection type                             | M12 plug |
| No. of poles                                | 5        |
| Leitungsanschlussrichtung zur Steckrichtung | 90°      |
| Steckgesichtskodierung Leitung/Adapter 1 1  | A coded  |

### Connection data

|                     |              |
|---------------------|--------------|
| Connection type (1) | Federtechnik |
|---------------------|--------------|

### Mechanical data

|                                     |            |
|-------------------------------------|------------|
| Connectable sheathed cable diameter | 6 ... 8 mm |
| Weight                              | 25 g       |

### Environmental Requirements

|                                         |               |
|-----------------------------------------|---------------|
| Surrounding air (operating) temperature | -25 ... 85 °C |
| Protection class                        | IP67          |

### Commercial data

|                    |               |
|--------------------|---------------|
| Country of origin  | DE            |
| GTIN               | 4050821114277 |
| Customs Tariff No. | 85369010000   |



Downloads

Documentation

System Description

|                                              |               |          |
|----------------------------------------------|---------------|----------|
| 767 Series, SPEEDWAY accessories, data sheet | pdf<br>1.0 MB | Download |
|----------------------------------------------|---------------|----------|

---

Subject to changes.

---