



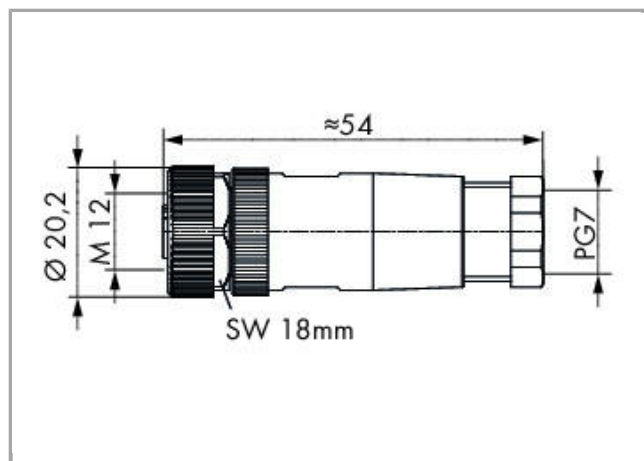

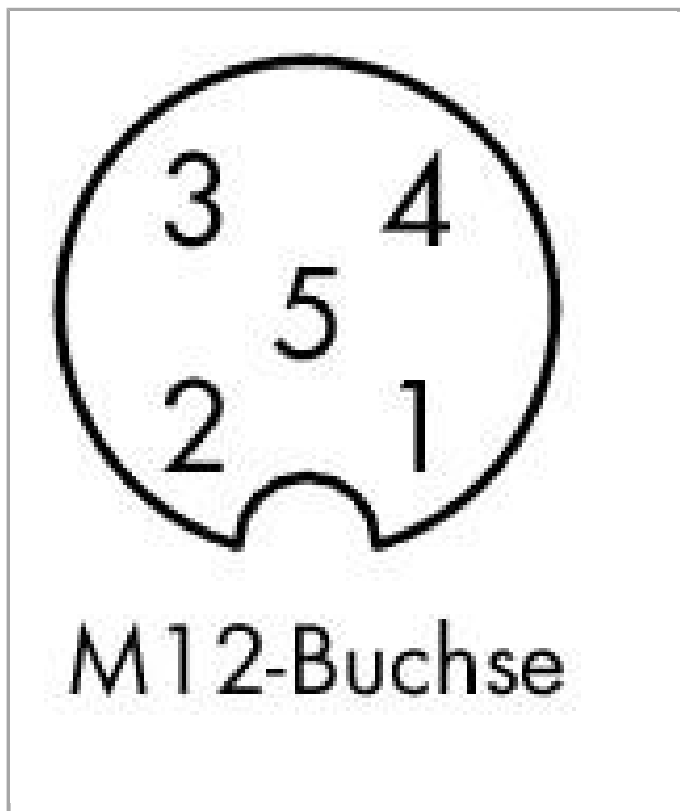

Conductor size

Ø 6 ... 8 mm / 0.14 - 0.5 mm²

Data

Technical Data

Connection type	M12 socket
No. of poles	5
Leitungsanschlussrichtung zur Steckrichtung	0°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded

Connection data

Connection type (1)	Federtechnik
---------------------	--------------

Mechanical data

Connectable sheathed cable diameter	4 ... 6 mm
Weight	25.2 g

Environmental Requirements

Protection class	IP67
------------------	------

Commercial data

Country of origin	DE
GTIN	4045454686123



Customs Tariff No. 85366990990

Downloads
Documentation

System Description

IP67 Cables and Pluggable Connectors	pdf 293.9 kB	Download
--------------------------------------	-----------------	----------

Subject to changes.
