





RoHS 
Compliant

[BOMcheck.net](https://www.bomcheck.net)

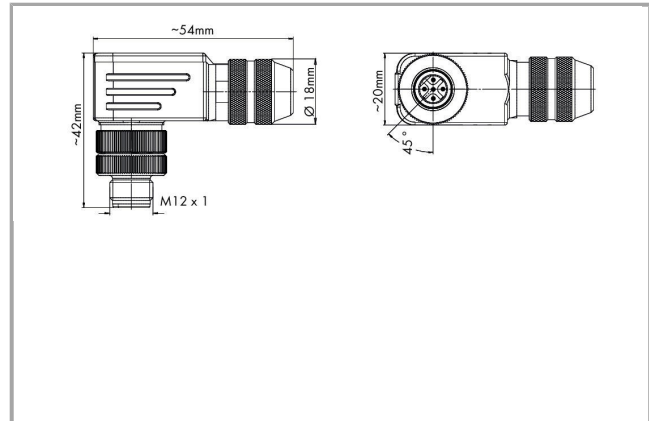

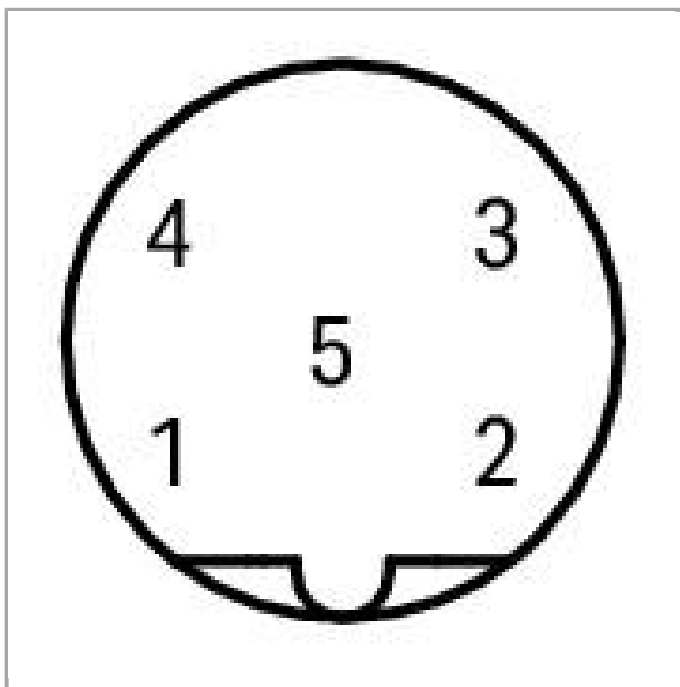

Anschließbare Leitung
Ø 6 ... 8 mm / 0,14 - 0,75 mm²

Data

Technical Data

Connection type	M12 plug
No. of poles	5
Anschlusspunkt geschirmt	yes
Leistungsanschlussrichtung zur Steckrichtung	90°
Steckgesichtskodierung Leitung/Adapter 1 1	B coded

Connection data

Connection type (1)	Schraubtechnik
---------------------	----------------

Mechanical data

Connectable sheathed cable diameter	6 ... 8 mm
Weight	44 g

Environmental Requirements

Surrounding air (operating) temperature	-40 ... 85 °C
Protection class	IP67

Commercial data

Product Group	23 (I/O passive and accessories)
Country of origin	DE
GTIN	4055143121545



Customs Tariff No.	85369010000
--------------------	-------------

Downloads
Documentation
System Description

767 Series, SPEEDWAY accessories, data sheet	pdf 1.0 MB	Download
--	---------------	----------

Subject to changes.
