



Data sheet | Item number: 762-5206/8000-001

Touch Panel 600; 54.6 cm (21.5"); 1920 x 1080 pixels; 2 x ETHERNET, 2 x USB, Audio; Visu Panel

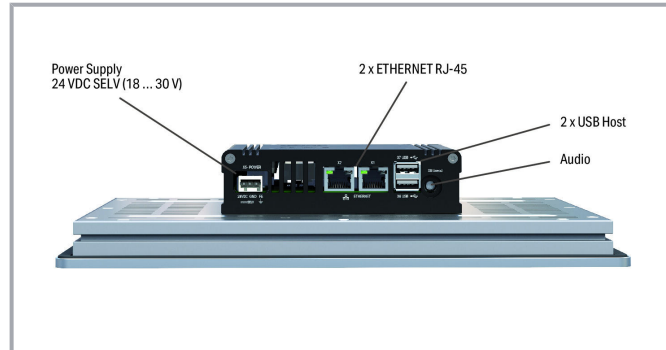

www.wago.com/762-5206_8000-001

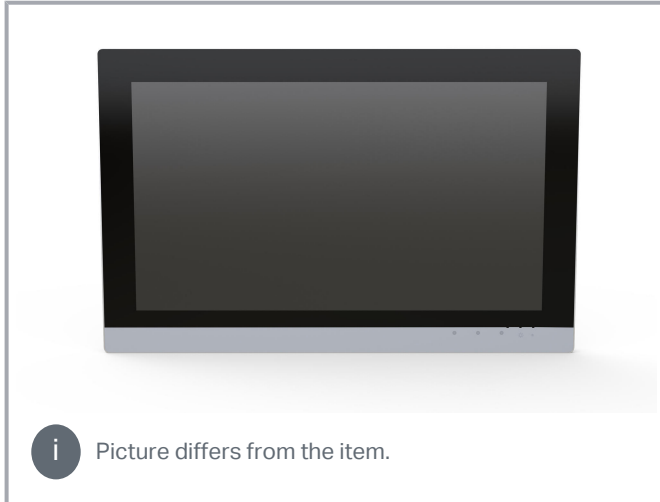

Item description

PIO2 hardware configuration

- 2 x ETHERNET port for connecting to field devices and the engineering tool
- 2 x USB port for optional connection of a USB stick, mouse or keyboard
- Audio interface for connecting a headphone or loudspeaker

Data

Technical data

Display diagonal	54.7 cm (21.5 Inches)
Display	Multitouch glass front; Capacitive touchscreen with a glass surface
Display colors	16.7 million colors
Graphics resolution	(1920 x 1080) px
Contrast ratio	1000:1
Viewing angle (horizontal/vertical)	89° / 89°
Brightness	350 cd/m ²
Visualization	Webserver Web Visu
ETHERNET protocols	DHCP DNS

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



FTP
FTPS
HTTP
HTTPS
SSH

Communication	EtherNet/IP™ Adapter (slave), library for e!RUNTIME (prerequisite: e!RUNTIME PLC 600 license) Modbus TCP Master/Slave (prerequisite: e!RUNTIME PLC 600 license) EtherCAT Master, requires an additional license (prerequisite: e!RUNTIME PLC 600 license) BACnet/IP, requires an additional license (prerequisite: e!RUNTIME PLC 600 license)
Operating system	Real-time Linux (with RT-Preempt patch)
Processor	ARM® Cortex™ A9
Programming environment	e!COCKPIT (based on CODESYS V3)
Main memory (RAM)	2,048 MB
Internal memory (flash)	4096 MB
Program memory	32 MB
Data memory	128 MB
Memory card type	microSD (max. 2 GB); microSDHC (max. 32 GB)
Indicators	Three-color LED (red, green, blue)
Controls	Capacitive (glass); 2 capacitive keys; proximity sensor
Supply voltage	24 VDC, SELV (18 ... 31.2 V); with reverse voltage protection
Operating power	7.9 W, without USB load; 13.4 W, with USB load

Connection data

Connection technology: communication/fieldbus	Modbus TCP: 2 x RJ-45; 2 x USB 2.0 host (type A)
---	--

Physical data

Width	554 mm / 21.811 inch
Height	358 mm / 14.094 inch
Depth	58 mm / 2.283 inch
Panel cutout (W x H)	(540 x 344) mm

Mechanical data

Weight	5600 g
--------	--------

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.

Environmental requirements


Surrounding air temperature (operation)	0 ... 45 °C (when mounted vertically; -0 ... +40 °C, other mounting positions)
Surrounding air temperature (storage)	-20 ... 60 °C
Protection type	IP65
Note on protection type	IP65 (front side); IP20 (rear side), per EN 60529
Relative humidity (without condensation)	90 %
Mounting type	Clamping elements (included)

Commercial data

Packaging type	BOX
Country of origin	DE
GTIN	4055144002706
Customs tariff number	8471410150

Approvals / Certificates

UL-Approvals



Logo	Approval	Additional Approval Text	Certificate name
	UL Underwriters Laboratories Inc. (ORDINARY LOCATIONS)	UL 61010-2-201	E175199

Optional accessories

Mounting







	Item no.: 762-9001 Clamping elements (4 pieces)	www.wago.com/762-9001
--	---	--

Software

	Item no.: 2759-208/211-1000 Library MTP; Single License; Online activation	www.wago.com/2759-208/211-1000
	Item no.: 2759-216/211-1000 e!RUNTIME; IEC 61131 runtime environment; 600; Single License; Online activation	www.wago.com/2759-216/211-1000

Subject to changes. Please also observe the further product documentation!



	Item no.: 2759-2286/211-1000 e!RUNTIME; BACnet; 600; M; Single License; Online activation	www.wago.com/2759-2286/211-1000
	Item no.: 2759-230/211-1000 e!RUNTIME; MicroBrowser; Single License; Online activation	www.wago.com/2759-230/211-1000
	Item no.: 2759-266/211-1000 e!RUNTIME; EtherCAT Master; 600; Single License; Online activation	www.wago.com/2759-266/211-1000
	Item no.: 2759-286/211-1000 e!RUNTIME; BACnet; 600; Single License; Online activation	www.wago.com/2759-286/211-1000
Memory card		
	Item no.: 758-879/000-3102 Memory Card SD Micro; 2 GByte	www.wago.com/758-879/000-3102
	Item no.: 758-879/000-3108 Memory Card SD Micro; pSLC-NAND; 8 GB; Temperature range: -40 to 90°C	www.wago.com/758-879/000-3108

Downloads

Documentation

Manual

WAGO Touch Panel 600 Advanced Line	V 1.5.0 Dec 1, 2020	pdf 2.4 MB	Download
---------------------------------------	------------------------	---------------	----------

Bid Text

762-5206/8000-001		docx 20.5 kB	Download
762-5206/8000-001		xml 7.3 kB	Download

System Description

Touch Panel 600, system description		pdf 727.2 kB	Download
-------------------------------------	--	-----------------	----------

Additional Information

WAGO OPC UA Server	V 1.1.0	pdf	Download
--------------------	---------	-----	----------

Subject to changes. Please also observe the further product documentation!



CAD files

CAD data

2D/3D Models 762-5206/8000-001	URL	Download
--------------------------------	---------------------	--------------------------

CAE data

ZUKEN Portal 762-5206/8000-001	URL	Download
--------------------------------	---------------------	--------------------------

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 762-5206/8000-001	URL	Download
--	---------------------	--------------------------

Touch Panel 600; 54.6 cm (21.5""); 1920 x 1080 pixels; 2 x ETHERNET, 2 x USB, Audio;
Visu Panel

Installation Notes

Product family

Touch Panel 600

[Show all products from the family](#)

Subject to changes. Please also observe the further product documentation!