



Data sheet | Item number: 762-6304/8000-002

Touch Panel 600; 25.7 cm (10.1"); 1280 x 800 pixels; 2 x ETHERNET, 2 x USB, CAN, DI/DO, RS-232/485, Audio; Control Panel

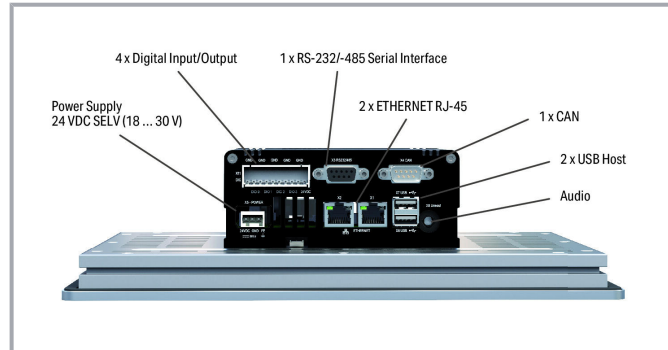

www.wago.com/762-6304_8000-002

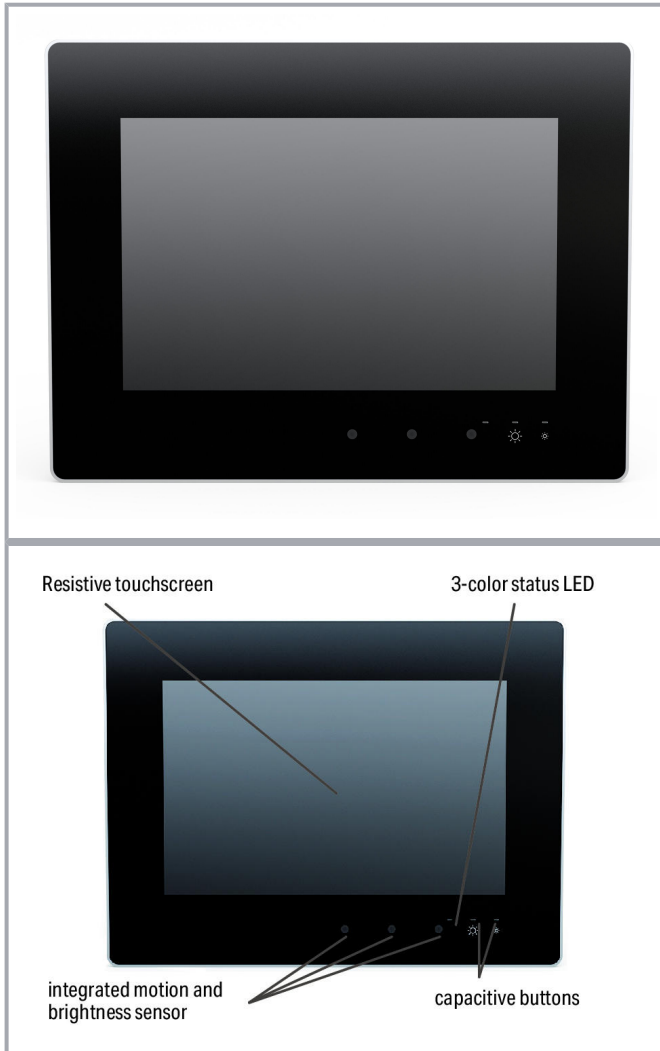

Item description

PIO3 hardware configuration

- 2 x ETHERNET port for connecting to field devices and the engineering tool
- 2 x USB port for optional connection of a USB stick, mouse or keyboard
- Audio interface for connecting a headphone or loudspeaker
- CAN for controlling field devices

—
Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



- RS-232/485 interface for controlling field devices equipped with a serial interface
- 4 x digital input/output for reading/triggering digital signals
- Power-failure-proof storage component

Data

Technical data

Display diagonal	25.7 cm (10.1 Inches)
Display	Resistive touchscreen (black front)
Display colors	16 million colors
Graphics resolution	(1280 x 800) px
Contrast ratio	800:1
Viewing angle (horizontal/vertical)	85° / 85°
Brightness	800 cd/m ²
Visualization	Webserver Web Visu Target Visu
ETHERNET protocols	DHCP DNS FTP FTPS HTTP HTTPS SSH
Communication	EtherNet/IP™ Adapter (slave), library for e!RUNTIME Modbus TCP Master/Slave CANopen Modbus (UDP) RS-232 serial interface RS-485 serial interface MQTT EtherCAT Master, requires an additional license BACnet/IP, requires an additional license
Operating system	Real-time Linux (with RT-Preempt patch)
Processor	ARM® Cortex™ A9
Programming environment	e!COCKPIT (based on CODESYS V3)
Main memory (RAM)	2,048 MB
Internal memory (flash)	4096 MB
Program memory	32 MB
Data memory	128 MB
Memory card type	microSD (max. 2 GB); microSDHC (max. 32 GB)

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



Indicators	Three-color LED (red, green, blue)
Controls	Resistive touch panel; 2 capacitive keys; proximity sensor
Supply voltage	24 VDC, SELV (18 ... 31.2 V); with reverse voltage protection
Operating power	11.8 W, without USB load; 17.0 W, with USB load

Connection data

Connection technology: communication/fieldbus	Modbus TCP/UDP: 2 x RJ-45; EtherNet/IP™: 2 x RJ-45; CANopen: 1 x D-sub 9 plug; Modbus UDP: 2 x RJ-45; RS-232 + RS-485 serial interface: 1 x D-sub 9 socket; USB: 2 x USB 2.0 host (type A)
---	--

Physical data

Width	293 mm / 11.535 inch
Height	223 mm / 8.78 inch
Depth	78 mm / 3.070 inch
Panel cutout (W x H)	(278 x 208) mm

Mechanical data

Weight	0 g
--------	-----

Environmental requirements

Surrounding air temperature (operation)	-20 ... 55 °C (when mounted vertically; -20 ... +50 °C, other mounting positions)
Surrounding air temperature (storage)	-20 ... 80 °C
Protection type	IP65
Note on protection type	IP65 (front side); IP20 (rear side), per EN 60529
Relative humidity (without condensation)	90 %
Mounting type	Clamping elements (included) or VESA mount (4 x M4x8)

Commercial data

Packaging type	BOX
Country of origin	DE
GTIN	4055143942898
Customs tariff number	8471410150

Approvals / Certificates


UL-Approvals

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
 Germantown, WI 53022
 Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
 Email: info.us@wago.com | Web: www.wago.us



Do you have any questions about our products?
 We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.








Logo	Approval	Additional Approval Text	Certificate name
	UL Underwriters Laboratories Inc. (ORDINARY LOCATIONS)	UL 61010-2-201	E175199

Optional accessories



Memory card

	Item no.: 758-879/000-3102 Memory Card SD Micro; 2 GByte	www.wago.com/758-879/000-3102
	Item no.: 758-879/000-3108 Memory Card SD Micro; pSLC-NAND; 8 GB; Temperature range: -40 to 90°C	www.wago.com/758-879/000-3108

Software

	Item no.: 2759-208/211-1000 Library MTP; Single License; Online activation	www.wago.com/2759-208/211-1000
	Item no.: 2759-2286/211-1000 e!RUNTIME; BACnet; 600; M; Single License; Online activation	www.wago.com/2759-2286/211-1000
	Item no.: 2759-230/211-1000 e!RUNTIME; MicroBrowser; Single License; Online activation	www.wago.com/2759-230/211-1000
	Item no.: 2759-266/211-1000 e!RUNTIME; EtherCAT Master; 600; Single License; Online activation	www.wago.com/2759-266/211-1000
	Item no.: 2759-286/211-1000 e!RUNTIME; BACnet; 600; Single License; Online activation	www.wago.com/2759-286/211-1000

Mounting

	Item no.: 762-9001 Clamping elements (4 pieces)	www.wago.com/762-9001
	Item no.: 762-9324 Flush-Mounted Housing for Touch Panel 600; 25.7 cm (10.1"); 80.0 mm	www.wago.com/762-9324

Downloads

Documentation

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.



Manual

WAGO Touch Panel 600 Marine Line	V 1.3.0 Dec 1, 2020	pdf 2.4 MB	Download
-------------------------------------	------------------------	---------------	----------

Bid Text

762-6304/8000-002		xml 6.9 kB	Download
-------------------	--	---------------	----------

762-6304/8000-002		docx 20.1 kB	Download
-------------------	--	-----------------	----------

System Description

Touch Panel 600, system description		pdf 727.2 kB	Download
-------------------------------------	--	-----------------	----------

Additional Information

WAGO OPC UA Server	V 1.1.0 Jan 28, 2021	pdf 1.2 MB	Download
--------------------	-------------------------	---------------	----------

CAD files

CAE data

ZUKEN Portal 762-6304/8000-002		URL	Download
--------------------------------	--	-----	----------

CAD data

2D/3D Models 762-6304/8000-002		URL	Download
--------------------------------	--	-----	----------

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 762-6304/8000-002 Touch Panel 600; 25.7 cm (10.1""); 1280 x 800 pixels; 2 x ETHERNET, 2 x USB, CAN, DI /DO, RS-232/485, Audio; Control Panel		URL	Download
--	--	-----	----------

Installation Notes

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.

Data sheet | Item number: 762-6304/8000-002

www.wago.com/762-6304_8000-002



Product family

Touch Panel 600

[Show all products from the family](#)

Subject to changes. Please also observe the further product documentation!

WAGO Corporation
Germantown, WI 53022
Phone: 1-800-DIN-RAIL (346-7245) | Fax: (262) 255-6222
Email: info.us@wago.com | Web: www.wago.us

Do you have any questions about our products?
We are always happy to take your call at (262) 255-6222 or 1 800-DIN-RAIL.