



Data sheet | Item number: 769-218/281-410

1-conductor/1-pin component carrier terminal block; with 2 jumper positions; with diode 1N4007; anode, left side; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm²; CAGE CLAMP®

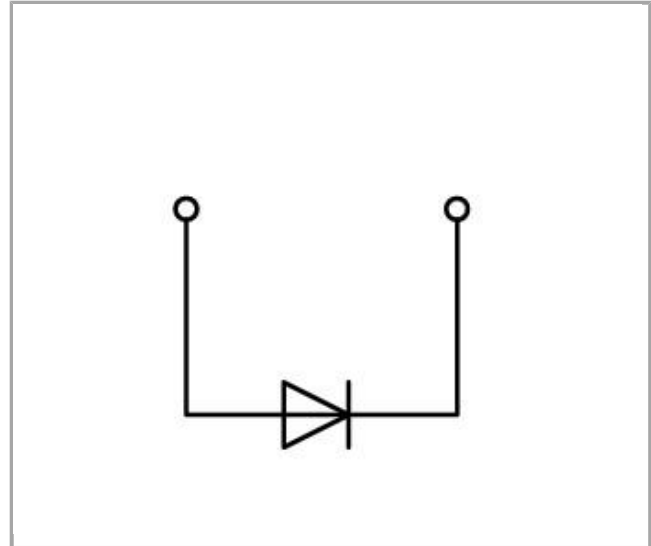

769-218/281-410

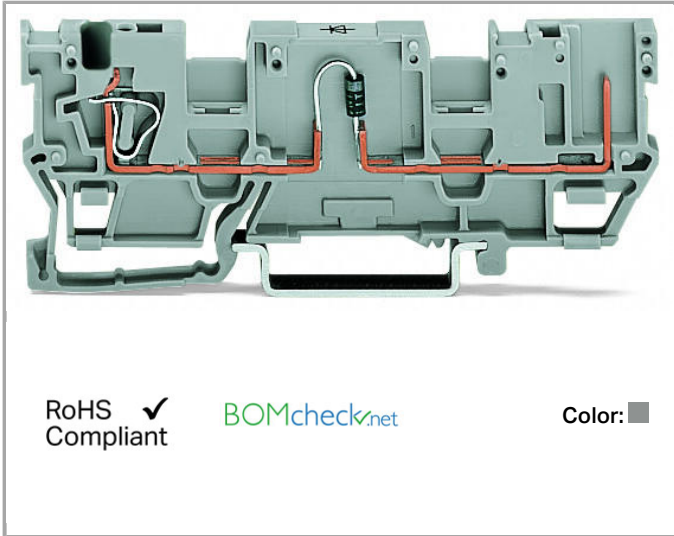

Data

Electrical data

Nominal voltage	250 V
Reverse voltage	1000 V

Ratings per IEC/EN 60664-1

Rated current	0.5 A
---------------	-------

Connection data

Connection technology	CAGE CLAMP®
Actuation type	Open Tool Slot
Connectable conductor materials	Copper
Nominal cross section	4 mm ²
Solid conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 inch
Total number of connection points	1
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	87.5 mm / 3.445 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

Material Data




Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.173 MJ
Weight	8.1 g

Commercial data

Product Group	18 (X-COM-System)
Country of origin	DE
GTIN	4045454198381
Customs Tariff No.	85369010000


Approvals / Certificates

Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60947	NTR NL-7626
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101144
	KEMA/KEUR DEKRA Certification B.V.	EN 60947	2190419.01











Ship Approvals

Certificate
















Logo	Approval	Additional Approval Text	name
	ABS American Bureau of Shipping	EN 60947	14- HG1293677- PDA
















Compatible products
















ferrule













 


	Item no.: 216-101 Ferrule; Sleeve for 0.5 mm ² / AWG 22; uninsulated; electro-tin plated	216-101
	Item no.: 216-102 Ferrule; Sleeve for 0.75 mm ² / AWG 20; uninsulated; electro-tin plated	216-102
	Item no.: 216-103 Ferrule; Sleeve for 1 mm ² / AWG 18; uninsulated; electro-tin plated	216-103
	Item no.: 216-104 Ferrule; Sleeve for 1.5 mm ² / AWG 16; uninsulated; electro-tin plated	216-104
	Item no.: 216-201 Ferrule; Sleeve for 0.5 mm ² / 20 AWG; insulated; electro-tin plated	216-201
	Item no.: 216-202 Ferrule; Sleeve for 0.75 mm ² / 18 AWG; insulated; electro-tin plated	216-202
	Item no.: 216-203 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated	216-203
	Item no.: 216-204 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated	216-204
	Item no.: 216-206 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated	216-206
	Item no.: 216-301 Ferrule; Sleeve for 0.25 mm ² / AWG 24; insulated; electro-tin plated	216-301
	Item no.: 216-302 Ferrule; Sleeve for 0.34 mm ² / 22 AWG; insulated; electro-tin plated	216-302





 






 



Female plug
















	Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole		769-101
	Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole	/000-006	769-101
	Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole	/000-016	769-101
	Item no.: 769-101/022-000 1-conductor female plug; angled; 4 mm ² ; 1-pole	/022-000	769-101
	Item no.: 769-101/022-016 1-conductor female plug; angled; 4 mm ² ; 1-pole	/022-016	769-101
	Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole		769-102
	Item no.: 769-102/000-006 1-conductor female plug; 4 mm ² ; 2-pole	/000-006	769-102
	Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole	/000-036	769-102
	Item no.: 769-102/000-037 1-conductor female plug; 4 mm ² ; 2-pole	/000-037	769-102
	Item no.: 769-102/022-000 1-conductor female plug; angled; 4 mm ² ; 2-pole	/022-000	769-102
	Item no.: 769-103 1-conductor female plug; 4 mm ² ; 3-pole		769-103
	Item no.: 769-103/000-006 1-conductor female plug; 4 mm ² ; 3-pole	/000-006	769-103
	Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole	/000-036	769-103
	Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole	/000-037	769-103
	Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole	/000-038	769-103

















	Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole	769-103 /000-039
	Item no.: 769-103/022-000 1-conductor female plug; angled; 4 mm ² ; 3-pole	769-103 /022-000
	Item no.: 769-104 1-conductor female plug; 4 mm ² ; 4-pole	769-104
	Item no.: 769-104/000-006 1-conductor female plug; 4 mm ² ; 4-pole	769-104 /000-006
	Item no.: 769-104/000-036 1-conductor female plug; 4 mm ² ; 4-pole	769-104 /000-036
	Item no.: 769-104/000-037 1-conductor female plug; 4 mm ² ; 4-pole	769-104 /000-037
	Item no.: 769-104/000-038 1-conductor female plug; 4 mm ² ; 4-pole	769-104 /000-038
	Item no.: 769-104/000-039 1-conductor female plug; 4 mm ² ; 4-pole	769-104 /000-039
	Item no.: 769-104/022-000 1-conductor female plug; angled; 4 mm ² ; 4-pole	769-104 /022-000
	Item no.: 769-105 1-conductor female plug; 4 mm ² ; 5-pole	769-105
	Item no.: 769-105/000-006 1-conductor female plug; 4 mm ² ; 5-pole	769-105 /000-006
	Item no.: 769-105/000-036 1-conductor female plug; 4 mm ² ; 5-pole	769-105 /000-036
	Item no.: 769-105/000-037 1-conductor female plug; 4 mm ² ; 5-pole	769-105 /000-037
	Item no.: 769-105/000-038 1-conductor female plug; 4 mm ² ; 5-pole	769-105 /000-038
	Item no.: 769-105/000-039 1-conductor female plug; 4 mm ² ; 5-pole	769-105 /000-039

	Item no.: 769-105/022-000 1-conductor female plug; angled; 4 mm ² ; 5-pole		769-105
		/022-000	
	Item no.: 769-106 1-conductor female plug; 4 mm ² ; 6-pole		769-106
	Item no.: 769-106/000-006 1-conductor female plug; 4 mm ² ; 6-pole		769-106
		/000-006	
	Item no.: 769-106/000-036 1-conductor female plug; 4 mm ² ; 6-pole		769-106
		/000-036	
	Item no.: 769-106/000-037 1-conductor female plug; 4 mm ² ; 6-pole		769-106
		/000-037	
	Item no.: 769-106/000-038 1-conductor female plug; 4 mm ² ; 6-pole		769-106
		/000-038	
	Item no.: 769-106/000-039 1-conductor female plug; 4 mm ² ; 6-pole		769-106
		/000-039	
	Item no.: 769-106/022-000 1-conductor female plug; angled; 4 mm ² ; 6-pole		769-106
		/022-000	
	Item no.: 769-107 1-conductor female plug; 4 mm ² ; 7-pole		769-107
	Item no.: 769-107/000-006 1-conductor female plug; 4 mm ² ; 7-pole		769-107
		/000-006	
	Item no.: 769-107/000-036 1-conductor female plug; 4 mm ² ; 7-pole		769-107
		/000-036	
	Item no.: 769-107/000-037 1-conductor female plug; 4 mm ² ; 7-pole		769-107
		/000-037	
	Item no.: 769-107/000-038 1-conductor female plug; 4 mm ² ; 7-pole		769-107
		/000-038	
	Item no.: 769-107/000-039 1-conductor female plug; 4 mm ² ; 7-pole		769-107
		/000-039	
	Item no.: 769-107/022-000 1-conductor female plug; angled; 4 mm ² ; 7-pole		769-107
		/022-000	
	Item no.: 769-108		

	1-conductor female plug; 4 mm ² ; 8-pole		769-108
	Item no.: 769-108/000-006 1-conductor female plug; 4 mm ² ; 8-pole	/000-006	769-108
	Item no.: 769-108/000-036 1-conductor female plug; 4 mm ² ; 8-pole	/000-036	769-108
	Item no.: 769-108/000-037 1-conductor female plug; 4 mm ² ; 8-pole	/000-037	769-108
	Item no.: 769-108/000-038 1-conductor female plug; 4 mm ² ; 8-pole	/000-038	769-108
	Item no.: 769-108/000-039 1-conductor female plug; 4 mm ² ; 8-pole	/000-039	769-108
	Item no.: 769-108/022-000 1-conductor female plug; angled; 4 mm ² ; 8-pole	/022-000	769-108
	Item no.: 769-109 1-conductor female plug; 4 mm ² ; 9-pole		769-109
	Item no.: 769-109/000-006 1-conductor female plug; 4 mm ² ; 9-pole	/000-006	769-109
	Item no.: 769-109/000-036 1-conductor female plug; 4 mm ² ; 9-pole	/000-036	769-109
	Item no.: 769-109/000-037 1-conductor female plug; 4 mm ² ; 9-pole	/000-037	769-109
	Item no.: 769-109/000-038 1-conductor female plug; 4 mm ² ; 9-pole	/000-038	769-109
	Item no.: 769-109/000-039 1-conductor female plug; 4 mm ² ; 9-pole	/000-039	769-109
	Item no.: 769-109/022-000 1-conductor female plug; angled; 4 mm ² ; 9-pole	/022-000	769-109
	Item no.: 769-110 1-conductor female plug; 4 mm ² ; 10-pole		769-110

	Item no.: 769-110/000-006 1-conductor female plug; 4 mm ² ; 10-pole	769-110
		/000-006
	Item no.: 769-110/000-036 1-conductor female plug; 4 mm ² ; 10-pole	769-110
		/000-036
	Item no.: 769-110/000-037 1-conductor female plug; 4 mm ² ; 10-pole	769-110
		/000-037
	Item no.: 769-110/000-038 1-conductor female plug; 4 mm ² ; 10-pole	769-110
		/000-038
	Item no.: 769-110/000-039 1-conductor female plug; 4 mm ² ; 10-pole	769-110
		/000-039
	Item no.: 769-110/022-000 1-conductor female plug; angled; 4 mm ² ; 10-pole	769-110
		/022-000
	Item no.: 769-111 1-conductor female plug; 4 mm ² ; 11-pole	769-111
	Item no.: 769-111/000-006 1-conductor female plug; 4 mm ² ; 11-pole	769-111
		/000-006
	Item no.: 769-111/000-036 1-conductor female plug; 4 mm ² ; 11-pole	769-111
		/000-036
	Item no.: 769-111/000-037 1-conductor female plug; 4 mm ² ; 11-pole	769-111
		/000-037
	Item no.: 769-111/000-038 1-conductor female plug; 4 mm ² ; 11-pole	769-111
		/000-038
	Item no.: 769-111/000-039 1-conductor female plug; 4 mm ² ; 11-pole	769-111
		/000-039
	Item no.: 769-111/022-000 1-conductor female plug; angled; 4 mm ² ; 11-pole	769-111
		/022-000
	Item no.: 769-112 1-conductor female plug; 4 mm ² ; 12-pole	769-112
	Item no.: 769-112/000-006 1-conductor female plug; 4 mm ² ; 12-pole	769-112
		/000-006

	Item no.: 769-112/000-036 1-conductor female plug; 4 mm ² ; 12-pole	/000-036	769-112
	Item no.: 769-112/000-037 1-conductor female plug; 4 mm ² ; 12-pole	/000-037	769-112
	Item no.: 769-112/000-038 1-conductor female plug; 4 mm ² ; 12-pole	/000-038	769-112
	Item no.: 769-112/000-039 1-conductor female plug; 4 mm ² ; 12-pole	/000-039	769-112
	Item no.: 769-112/022-000 1-conductor female plug; angled; 4 mm ² ; 12-pole	/022-000	769-112
	Item no.: 769-113 1-conductor female plug; 4 mm ² ; 13-pole		769-113
	Item no.: 769-113/000-036 1-conductor female plug; 4 mm ² ; 13-pole	/000-036	769-113
	Item no.: 769-113/000-037 1-conductor female plug; 4 mm ² ; 13-pole	/000-037	769-113
	Item no.: 769-113/000-038 1-conductor female plug; 4 mm ² ; 13-pole	/000-038	769-113
	Item no.: 769-113/000-039 1-conductor female plug; 4 mm ² ; 13-pole	/000-039	769-113
	Item no.: 769-113/022-000 1-conductor female plug; angled; 4 mm ² ; 13-pole	/022-000	769-113
	Item no.: 769-114 1-conductor female plug; 4 mm ² ; 14-pole		769-114
	Item no.: 769-114/000-006 1-conductor female plug; 4 mm ² ; 14-pole	/000-006	769-114
	Item no.: 769-114/000-036 1-conductor female plug; 4 mm ² ; 14-pole	/000-036	769-114
	Item no.: 769-114/000-037 1-conductor female plug; 4 mm ² ; 14-pole	/000-037	769-114

	Item no.: 769-114/000-038 1-conductor female plug; 4 mm ² ; 14-pole		769-114
		/000-038	
	Item no.: 769-114/000-039 1-conductor female plug; 4 mm ² ; 14-pole		769-114
		/000-039	
	Item no.: 769-114/022-000 1-conductor female plug; angled; 4 mm ² ; 14-pole		769-114
		/022-000	
	Item no.: 769-115 1-conductor female plug; 4 mm ² ; 15-pole		769-115
	Item no.: 769-115/000-036 1-conductor female plug; 4 mm ² ; 15-pole		769-115
		/000-036	
	Item no.: 769-115/000-037 1-conductor female plug; 4 mm ² ; 15-pole		769-115
		/000-037	
	Item no.: 769-115/000-038 1-conductor female plug; 4 mm ² ; 15-pole		769-115
		/000-038	
	Item no.: 769-115/000-039 1-conductor female plug; 4 mm ² ; 15-pole		769-115
		/000-039	
	Item no.: 769-115/022-000 1-conductor female plug; angled; 4 mm ² ; 15-pole		769-115
		/022-000	
	Item no.: 769-121 2-conductor female connector; 4 mm ² ; 1-pole		769-121
	Item no.: 769-121/000-016 2-conductor female connector; 4 mm ² ; 1-pole		769-121
		/000-016	
	Item no.: 769-122 2-conductor female connector; 4 mm ² ; 2-pole		769-122
	Item no.: 769-123 2-conductor female connector; 4 mm ² ; 3-pole		769-123
	Item no.: 769-124 2-conductor female connector; 4 mm ² ; 4-pole		769-124
	Item no.: 769-125 2-conductor female connector; 4 mm ² ; 5-pole		769-125
	Item no.: 769-126 2-conductor female connector; 4 mm ² ; 6-pole		769-126
	Item no.: 769-127 2-conductor female connector; 4 mm ² ; 7-pole		769-127

**Item no.: 769-128**2-conductor female connector; 4 mm²; 8-pole

769-128

Item no.: 769-1292-conductor female connector; 4 mm²; 9-pole

769-129

Item no.: 769-1302-conductor female connector; 4 mm²; 10-pole

769-130

Item no.: 769-1312-conductor female connector; 4 mm²; 11-pole

769-131

Item no.: 769-1322-conductor female connector; 4 mm²; 12-pole

769-132

Item no.: 769-1332-conductor female connector; 4 mm²; 13-pole

769-133

Item no.: 769-1342-conductor female connector; 4 mm²; 14-pole

769-134

Item no.: 769-1352-conductor female connector; 4 mm²; 15-pole

769-135

Jumper**Item no.: 249-123**Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm²

249-123

**Item no.: 249-125**Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²

249-125

**Item no.: 249-126**Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²

249-126

**Item no.: 249-127**Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²

249-127

**Item no.: 280-402**

Adjacent jumper; insulated; IN = IN terminal block

280-402

**Item no.: 280-409**

Alternate jumper; insulated; IN = IN terminal block

280-409

**Item no.: 780-452**

Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs

780-452

**Item no.: 780-453**

Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs

780-453

**Item no.: 780-454**


















Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs

















780-454
















**Item no.: 780-455**
















Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs

780-455

	Item no.: 780-456 Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs	780-456
	Item no.: 780-457 Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs	780-457
	Item no.: 780-458 Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs	780-458
General accessories		
	Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm ² - 4 mm ² tbs	280-404
	Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar	280-418
	Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks	280-419
	Item no.: 769-438 Pin cover; with marker slot for miniature WSB	769-438
	Item no.: 769-439 Pin cover; with marker slot for miniature WSB	769-439
	Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	769-501
	Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole	769-501 /UUU-UUb
	Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	769-501 /UUU-U 1b
	Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	769-502
	Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	769-502 /UUU-UUb
	Item no.: 769-502/000-016 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	769-502 /UUU-U 1b
	Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503
	Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503 /UUU-UUb
	Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503 /UUU-U 1b

	Item no.: 769-504 Start module for 2-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole		769-504
	Item no.: 769-504/000-006 Start module for 2-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	/UUU-UUB	769-504
	Item no.: 769-504/000-016 Start module for 2-conductor female connector; 4 mm ² ; 1-pole	/UUU-UUB	769-504
	Item no.: 769-505 Center module for 2-conductor female connector; 4 mm ² ; 1-pole		769-505
	Item no.: 769-505/000-006 Center module for 2-conductor female connector; 4 mm ² ; 1-pole	/UUU-UUB	769-505
	Item no.: 769-505/000-016 Center module for 2-conductor female connector; 4 mm ² ; 1-pole	/UUU-UUB	769-505
	Item no.: 769-506 End module for 2-conductor female connector; 4 mm ² ; 1-pole		769-506
	Item no.: 769-506/000-006 End module for 2-conductor female connector; 4 mm ² ; 1-pole	/UUU-UUB	769-506
	Item no.: 769-506/000-016 End module for 2-conductor female connector; 4 mm ² ; 1-pole	/UUU-UUB	769-506
	Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole		769-512
	Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	/UUU-UUB	769-512
	Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	/UUU-UUB	769-512
	Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm ² ; 1-pole		769-513
	Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole	/UUU-UUB	769-513
	Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole	/UUU-UUB	769-513
	Item no.: 769-515 1-conductor end module; angled; codable; 1-pole		769-515

	Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole	769-515 /000-006
	Item no.: 769-515/000-016 1-conductor end module; angled; codable; 1-pole	769-515 /000-016
tools		
	Item no.: 210-720 Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm	210-720
End plate		
	Item no.: 769-311 End and intermediate plate; 1.1 mm thick	769-311
	Item no.: 769-312 End and intermediate plate; 1.1 mm thick	769-312
	Item no.: 769-314 Separator plate; 1.1 mm thick; oversized	769-314
Protective Warning Marker		
	Item no.: 280-415 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	280-415
Marking accessories		
	Item no.: 2009-145 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-002
	Item no.: 2009-145/000-005 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-005
	Item no.: 2009-145/000-006 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-006
	Item no.: 2009-145/000-007 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-007
	Item no.: 2009-145/000-012 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-012
	Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-023
	Item no.: 2009-145/000-024 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-145 /000-024

	Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card	248-501
	Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-002
	Item no.: 248-501/000-005 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-005
	Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-006
	Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-007
	Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-012
	Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-017
	Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-023
	Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-024
assembling		
	Item no.: 209-106 Mounting carrier; for isolated mounting on DIN 35 rails	209-106
Insulation stop		
	Item no.: 769-470 Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 5 pieces/strip	769-470
	Item no.: 769-471 Insulation stop; 0.25 - 0.5 mm²; 5 pieces/strip	769-471
	Item no.: 769-472 Insulation stop; 0.75 - 1 mm²; 5 pieces/strip	769-472
check		
	Item no.: 210-136 Test plug; 2 mm Ø; with 500 mm cable	210-136
	Item no.: 210-137 Test plug; 2.3 mm Ø; with 500 mm cable	210-137
Carrier rail		
	Item no.: 210-112	

	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	210-112
	Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	210-113
	Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	210-114
	Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	210-115
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-118
	Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	210-196
	Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	210-197
	Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-198
	Item no.: 210-504 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	210-504
	Item no.: 210-505 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	210-505
	Item no.: 210-506 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715	210-506
	Item no.: 210-508 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715	210-508
Coding		
	Item no.: 769-435 Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors	769-435

Downloads

Documentation

Bid Text

769-218/281-410	doc 25.6 kB	Download
-----------------	----------------	----------

CAD/CAE - Smart Data

CAD data

3D Download 769-218/281-410	URL	Download
-----------------------------	-----	----------



Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.
