


Data sheet | Item number: 769-615/005-000

1-conductor male connector; Snap-in flange; 4 mm²; Pin spacing 5 mm; 15-pole; 4,00 mm²; gray




769-615_005-000

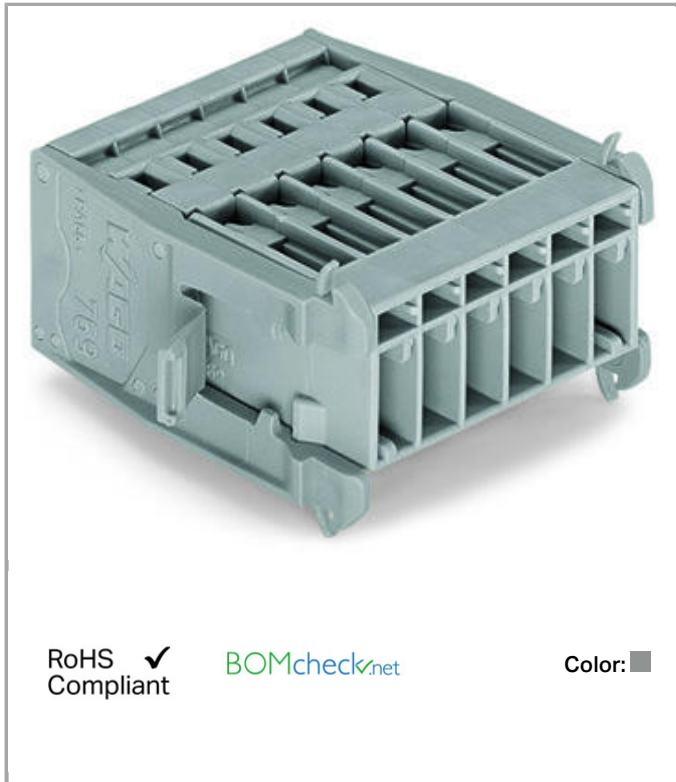

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color: ■

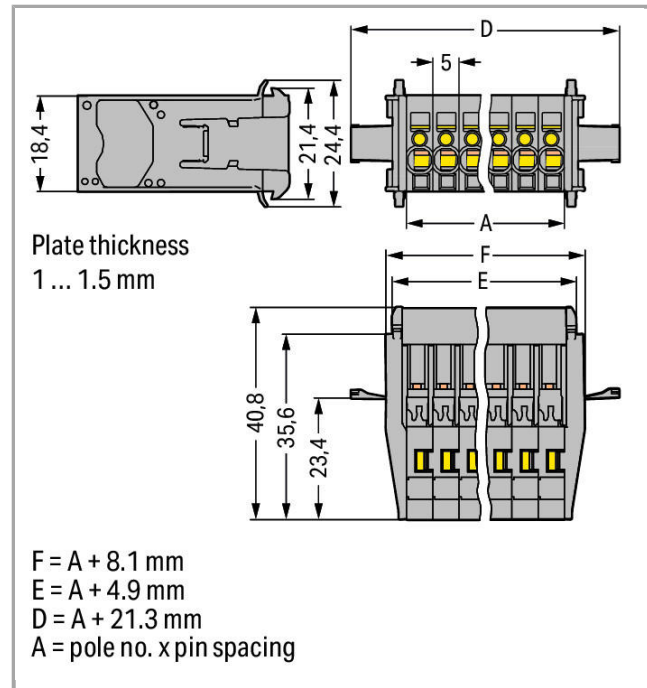

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	32 A

Connection data

Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper
Nominal cross section	4 mm ²
Solid conductor	0.08 4 mm ² / 28 12 AWG
Fine-stranded conductor	0.08 4 mm ² / 28 12 AWG
Strip length	8 9 mm / 0.31 0.35 inch
Total number of connection points	15

Total number of potentials	15
Type of wiring	Front-entry wiring
No. of poles	15

Geometrical Data

Pin spacing	5 mm / 0.197 inch
Width	96.3 mm / 3.791 inch
Height	24.4 mm / 0.961 inch
Depth	40.8 mm / 1.606 inch

Mechanical data

Mounting type	Snap-in
---------------	---------

Plug connection

Contact type (pluggable connector)	Male connector/plug
Connector connection type	for conductors

Material Data


Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.906 MJ
Weight	45.23 g

Commercial data

Product Group	18 (X-COM-System)
Country of origin	PL
GTIN	4044918854559
Customs Tariff No.	85366990990



Approvals / Certificates

Radio-Approvals



Logo	Approval	Additional Approval Text	Certificate name
	CCA	EN 61984	2190419.02
	CCA	IEC 61984	NL-47799
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101144





Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 61984	2190419.02
	CCA DEKRA Certification B.V.	IEC 61984	NL-47799
	CSA DEKRA Certification B.V.	C22.2 No. 158	1101144

Other Approvals















Logo	Approval	Additional Approval Text	Certificate name
	UR Underwriters Laboratories Inc.	UL 1977	E45171
	UR Underwriters Laboratories Inc.	UL 1059	E45172
	UR Underwriters Laboratories Inc.	UL 1059	E45172
















UL-Approvals
















Logo	Approval	Additional Approval Text	Certificate name
	UR Underwriters Laboratories Inc.	UL 1059	31.07.2019- E45172
	UR Underwriters Laboratories Inc.	UL 1977	E45171- 20010720
	UR Underwriters Laboratories Inc.	UL 1977	E45171- 20010720

Compatible products

Marking accessories

	Item no.: 2009-145 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; white		2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; yellow	/000-002	2009-145
	Item no.: 2009-145/000-005 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; red	/000-005	2009-145
	Item no.: 2009-145/000-006 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; blue	/000-006	2009-145
	Item no.: 2009-145/000-007 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; gray	/000-007	2009-145
	Item no.: 2009-145/000-012 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; orange	/000-012	2009-145
	Item no.: 2009-145/000-023 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; green	/000-023	2009-145
	Item no.: 2009-145/000-024 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; violet	/000-024	2009-145
	Item no.: 210-831 Marking strips; on reel; 2.3 mm wide; plain; Self-adhesive; white		210-831
	Item no.: 210-832 Marking strips; on reel; 3 mm wide; plain; Self-adhesive; white		210-832
	Item no.: 210-833 Marking strips; on reel; 6 mm wide; plain; Self-adhesive; white		210-833
	Item no.: 210-834 Marking strips; on reel; 5 mm wide; plain; Self-adhesive; white		210-834
	Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card		248-501
	Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; yellow	/000-002	248-501

	Item no.: 248-501/000-005 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-005
	Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-006
	Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-007
	Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-012
	Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-017
	Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-023
	Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white	248-501 /000-024
tools		
	Item no.: 210-490 Operating tool; for female and male connectors with CAGE CLAMP® connection	210-490
	Item no.: 769-434 Push-button; loose	769-434
Female plug		
	Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole; 4,00 mm ² ; gray	769-101
	Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole; 4,00 mm ² ; green-yellow	769-101 /000-016
	Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole; 4,00 mm ² ; gray	769-102
	Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole; 4,00 mm ² ; gray, green-yellow	769-102 /000-036
	Item no.: 769-102/000-037 1-conductor female plug; 4 mm ² ; 2-pole; 4,00 mm ² ; green-yellow, gray	769-102 /000-037
	Item no.: 769-103 1-conductor female plug; 4 mm ² ; 3-pole; 4,00 mm ² ; gray	769-103

	Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole; 4,00 mm ² ; gray, green-yellow	769-103 /000-036
	Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole; 4,00 mm ² ; green-yellow, gray	769-103 /000-037
	Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole; 4,00 mm ² ; gray, blue, green-yellow	769-103 /000-038
	Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole; 4,00 mm ² ; green-yellow, blue, gray	769-103 /000-039
	Item no.: 769-104 1-conductor female plug; 4 mm ² ; 4-pole; 4,00 mm ² ; gray	769-104
	Item no.: 769-104/000-036 1-conductor female plug; 4 mm ² ; 4-pole; 4,00 mm ² ; gray, green-yellow	769-104 /000-036
	Item no.: 769-104/000-037 1-conductor female plug; 4 mm ² ; 4-pole; 4,00 mm ² ; green-yellow, gray	769-104 /000-037
	Item no.: 769-104/000-038 1-conductor female plug; 4 mm ² ; 4-pole; 4,00 mm ² ; gray, blue, green-yellow	769-104 /000-038
	Item no.: 769-104/000-039 1-conductor female plug; 4 mm ² ; 4-pole; 4,00 mm ² ; green-yellow, blue, gray	769-104 /000-039
	Item no.: 769-105 1-conductor female plug; 4 mm ² ; 5-pole; 4,00 mm ² ; gray	769-105
	Item no.: 769-105/000-036 1-conductor female plug; 4 mm ² ; 5-pole; 4,00 mm ² ; gray, green-yellow	769-105 /000-036
	Item no.: 769-105/000-037 1-conductor female plug; 4 mm ² ; 5-pole; 4,00 mm ² ; green-yellow, gray	769-105 /000-037
	Item no.: 769-105/000-038 1-conductor female plug; 4 mm ² ; 5-pole; 4,00 mm ² ; gray, blue, green-yellow	769-105 /000-038
	Item no.: 769-105/000-039 1-conductor female plug; 4 mm ² ; 5-pole; 4,00 mm ² ; green-yellow, blue, gray	769-105 /000-039
	Item no.: 769-106 1-conductor female plug; 4 mm ² ; 6-pole; 4,00 mm ² ; gray	769-106
	Item no.: 769-106/000-006 1-conductor female plug; 4 mm ² ; 6-pole; 4,00 mm ² ; blue	769-106 /000-006

**Item no.: 769-106/000-036**1-conductor female plug; 4 mm²; 6-pole; 4,00 mm²; gray, green-yellow

/000-036

769-106

Item no.: 769-106/000-0371-conductor female plug; 4 mm²; 6-pole; 4,00 mm²; green-yellow, gray

/000-037

769-106

Item no.: 769-106/000-0381-conductor female plug; 4 mm²; 6-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-106

Item no.: 769-106/000-0391-conductor female plug; 4 mm²; 6-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-106

Item no.: 769-1071-conductor female plug; 4 mm²; 7-pole; 4,00 mm²; gray

769-107

Item no.: 769-107/000-0361-conductor female plug; 4 mm²; 7-pole; 4,00 mm²; gray, green-yellow

/000-036

769-107

Item no.: 769-107/000-0371-conductor female plug; 4 mm²; 7-pole; 4,00 mm²; green-yellow, gray

/000-037

769-107

Item no.: 769-107/000-0381-conductor female plug; 4 mm²; 7-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-107

Item no.: 769-107/000-0391-conductor female plug; 4 mm²; 7-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-107

Item no.: 769-1081-conductor female plug; 4 mm²; 8-pole; 4,00 mm²; gray

769-108

Item no.: 769-108/000-0361-conductor female plug; 4 mm²; 8-pole; 4,00 mm²; gray, green-yellow

/000-036

769-108

Item no.: 769-108/000-0371-conductor female plug; 4 mm²; 8-pole; 4,00 mm²; green-yellow, gray

/000-037

769-108

Item no.: 769-108/000-0381-conductor female plug; 4 mm²; 8-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-108

Item no.: 769-108/000-0391-conductor female plug; 4 mm²; 8-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-108

Item no.: 769-1091-conductor female plug; 4 mm²; 9-pole; 4,00 mm²; gray

769-109

**Item no.: 769-109/000-036**1-conductor female plug; 4 mm²; 9-pole; 4,00 mm²; gray, green-yellow

/000-036

769-109

**Item no.: 769-109/000-037**1-conductor female plug; 4 mm²; 9-pole; 4,00 mm²; green-yellow, gray

/000-037

769-109

**Item no.: 769-109/000-038**1-conductor female plug; 4 mm²; 9-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-109

**Item no.: 769-109/000-039**1-conductor female plug; 4 mm²; 9-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-109

**Item no.: 769-110**1-conductor female plug; 4 mm²; 10-pole; 4,00 mm²; gray

769-110

**Item no.: 769-110/000-036**1-conductor female plug; 4 mm²; 10-pole; 4,00 mm²; gray, green-yellow

/000-036

769-110

**Item no.: 769-110/000-037**1-conductor female plug; 4 mm²; 10-pole; 4,00 mm²; green-yellow, gray

/000-037

769-110

**Item no.: 769-110/000-038**1-conductor female plug; 4 mm²; 10-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-110

**Item no.: 769-110/000-039**1-conductor female plug; 4 mm²; 10-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-110

**Item no.: 769-111**1-conductor female plug; 4 mm²; 11-pole; 4,00 mm²; gray

769-111

**Item no.: 769-111/000-036**1-conductor female plug; 4 mm²; 11-pole; 4,00 mm²; gray, green-yellow

/000-036

769-111

**Item no.: 769-111/000-037**1-conductor female plug; 4 mm²; 11-pole; 4,00 mm²; green-yellow, gray

/000-037

769-111

**Item no.: 769-111/000-038**1-conductor female plug; 4 mm²; 11-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-111

**Item no.: 769-111/000-039**1-conductor female plug; 4 mm²; 11-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-111

Item no.: 769-1121-conductor female plug; 4 mm²; 12-pole; 4,00 mm²; gray

769-112

**Item no.: 769-112/000-036**1-conductor female plug; 4 mm²; 12-pole; 4,00 mm²; gray, green-yellow

/000-036

769-112

**Item no.: 769-112/000-037**1-conductor female plug; 4 mm²; 12-pole; 4,00 mm²; green-yellow, gray

/000-037

769-112

**Item no.: 769-112/000-038**1-conductor female plug; 4 mm²; 12-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-112

**Item no.: 769-112/000-039**1-conductor female plug; 4 mm²; 12-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-112

**Item no.: 769-113**1-conductor female plug; 4 mm²; 13-pole; 4,00 mm²; gray

769-113

**Item no.: 769-113/000-036**1-conductor female plug; 4 mm²; 13-pole; 4,00 mm²; gray, green-yellow

/000-036

769-113

**Item no.: 769-113/000-037**1-conductor female plug; 4 mm²; 13-pole; 4,00 mm²; green-yellow, gray

/000-037

769-113

**Item no.: 769-113/000-038**1-conductor female plug; 4 mm²; 13-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-113

**Item no.: 769-113/000-039**1-conductor female plug; 4 mm²; 13-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-113

**Item no.: 769-114**1-conductor female plug; 4 mm²; 14-pole; 4,00 mm²; gray

769-114

**Item no.: 769-114/000-036**1-conductor female plug; 4 mm²; 14-pole; 4,00 mm²; gray, green-yellow

/000-036

769-114

**Item no.: 769-114/000-037**1-conductor female plug; 4 mm²; 14-pole; 4,00 mm²; green-yellow, gray

/000-037

769-114

**Item no.: 769-114/000-038**1-conductor female plug; 4 mm²; 14-pole; 4,00 mm²; gray, blue, green-yellow

/000-038

769-114

**Item no.: 769-114/000-039**1-conductor female plug; 4 mm²; 14-pole; 4,00 mm²; green-yellow, blue, gray

/000-039

769-114

Item no.: 769-1151-conductor female plug; 4 mm²; 15-pole; 4,00 mm²; gray

769-115

**Item no.: 769-115/000-036**1-conductor female plug; 4 mm²; 15-pole; 4,00 mm2; gray, green-yellow

/000-036

769-115

**Item no.: 769-115/000-037**1-conductor female plug; 4 mm²; 15-pole; 4,00 mm2; green-yellow, gray

/000-037

769-115

**Item no.: 769-115/000-038**1-conductor female plug; 4 mm²; 15-pole; 4,00 mm2; gray, blue, green-yellow

/000-038

769-115

**Item no.: 769-115/000-039**1-conductor female plug; 4 mm²; 15-pole; 4,00 mm2; green-yellow, blue, gray

/000-039

769-115

**Item no.: 769-115/021-000**1-conductor female plug; Locking lever; 4 mm²; 15-pole; 4,00 mm2; gray

/021-000

769-115

**Item no.: 769-121**2-conductor female connector; 4 mm²; 1-pole; 4,00 mm2; gray

769-121

**Item no.: 769-121/000-016**2-conductor female connector; 4 mm²; 1-pole; 4,00 mm2; green-yellow

/000-016

769-121

**Item no.: 769-122**2-conductor female connector; 4 mm²; 2-pole; 4,00 mm2; gray

769-122

**Item no.: 769-123**2-conductor female connector; 4 mm²; 3-pole; 4,00 mm2; gray

769-123

**Item no.: 769-124**2-conductor female connector; 4 mm²; 4-pole; 4,00 mm2; gray

769-124

**Item no.: 769-125**2-conductor female connector; 4 mm²; 5-pole; 4,00 mm2; gray

769-125

**Item no.: 769-126**2-conductor female connector; 4 mm²; 6-pole; 4,00 mm2; gray

769-126

**Item no.: 769-127**2-conductor female connector; 4 mm²; 7-pole; 4,00 mm2; gray

769-127

**Item no.: 769-128**2-conductor female connector; 4 mm²; 8-pole; 4,00 mm2; gray

769-128

**Item no.: 769-129**2-conductor female connector; 4 mm²; 9-pole; 4,00 mm2; gray









 









769-129

**Item no.: 769-130**2-conductor female connector; 4 mm²; 10-pole; 4,00 mm2; gray

769-130

**Item no.: 769-131**2-conductor female connector; 4 mm²; 11-pole; 4,00 mm2; gray

769-131

	Item no.: 769-132 2-conductor female connector; 4 mm ² ; 12-pole; 4,00 mm2; gray	769-132
	Item no.: 769-133 2-conductor female connector; 4 mm ² ; 13-pole; 4,00 mm2; gray	769-133
	Item no.: 769-134 2-conductor female connector; 4 mm ² ; 14-pole; 4,00 mm2; gray	769-134
	Item no.: 769-135 2-conductor female connector; 4 mm ² ; 15-pole; 4,00 mm2; gray	769-135
Insulation stop		
	Item no.: 769-470 Insulation stop; 0.08 - 0.2 mm ² "s" (0.14 mm ² "f-st"); 5 pieces/strip; white	769-470
	Item no.: 769-471 Insulation stop; 0.25 - 0.5 mm ² ; 5 pieces/strip; light gray	769-471
	Item no.: 769-472 Insulation stop; 0.75 - 1 mm ² ; 5 pieces/strip; dark gray	769-472
Strain relief plate		
	Item no.: 769-410 Strain relief plate; gray	769-410
	Item no.: 769-414 Strain relief plate; gray	769-414
Coding		
	Item no.: 769-435 Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors; orange	769-435
ferrule		
	Item no.: 216-101 Ferrule; Sleeve for 0.5 mm ² / AWG 22; uninsulated; electro-tin plated	216-101
	Item no.: 216-102 Ferrule; Sleeve for 0.75 mm ² / AWG 20; uninsulated; electro-tin plated	216-102
	Item no.: 216-103 Ferrule; Sleeve for 1 mm ² / AWG 18; uninsulated; electro-tin plated	216-103
	Item no.: 216-104 Ferrule; Sleeve for 1.5 mm ² / AWG 16; uninsulated; electro-tin plated	216-104
	Item no.: 216-201 Ferrule; Sleeve for 0.5 mm ² / 20 AWG; insulated; electro-tin plated; white	216-201
	Item no.: 216-202 Ferrule; Sleeve for 0.75 mm ² / 18 AWG; insulated; electro-tin plated; gray	216-202
	Item no.: 216-203 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; red	216-203
	Item no.: 216-204 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; black	216-204



Item no.: 216-206
 Ferrule; Sleeve for 2.5 mm² / AWG 14; insulated; electro-tin plated; blue

216-206

Protective Warning Marker



Item no.: 280-415
 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks; yellow

280-415

Downloads

Documentation

Bid Text

769-615/005-000		doc 25.6 kB	Download
-----------------	--	----------------	----------

Additional Information

Technical explanations	Apr 3, 2019	pdf 2.1 MB	Download
------------------------	-------------	---------------	----------

CAD/CAE - Smart Data

CAD data

3D Download 769-615/005-000		URL	Download
-----------------------------	--	-----	----------

EPLAN

EPLAN Data Portal			Download
-------------------	--	--	----------

WSCAD

WSCAD Universe			Download
----------------	--	--	----------

Product family

X-COM
[Show all products from the family](#)

Subject to changes.