


Data sheet | Item number: 770-140

Locking lever; for sockets; for manual operation

770-140

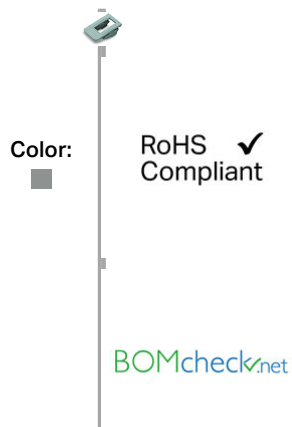

Data

Electrical data

Note on Contact Resistance

approx. 1m Ω contact resistance

approx. 0.25m Ω contact transition plug/socket

Mechanical data

Protection class

IP20

Note on protection class

Only in mated condition with strain relief housing (These compact connectors are not designed for use in open, easily accessible areas.)

Plug connection

Mismating protection

Yes

Locking of plug-in connection

locking lever

Material Data

Color

gray

Insulating material

Polyamide 66 (PA 66)

Flammability class per UL94

V0

Contact material

Copper or copper alloy, surface-treated

Fire load

0.015 MJ



Weight	0.51 g
--------	--------

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
Processing temperature	-5 ... +40 °C
Continuous operating temperature	-35 ... +85 °C
Note on Continuous Service Temperature	Insulating parts for temperatures \leq 105 °C

Commercial data

Product Group	20 (WINSTA)
Country of origin	DE
GTIN	4050821601364
Customs Tariff No.	39269097900

Downloads

Documentation

Bid Text

770-140	doc 22.0 kB	Download
---------	----------------	----------

CAD/CAE - Smart Data

CAD data

3D Download 770-140	URL	Download
---------------------	-----	----------

Subject to changes.
