



## Data sheet | Item number: 770-502/041-000

Strain relief housing; 2-pole; with locking clip; for 1 cable; 7.0 ... 10.5 mm; 35 mm; black

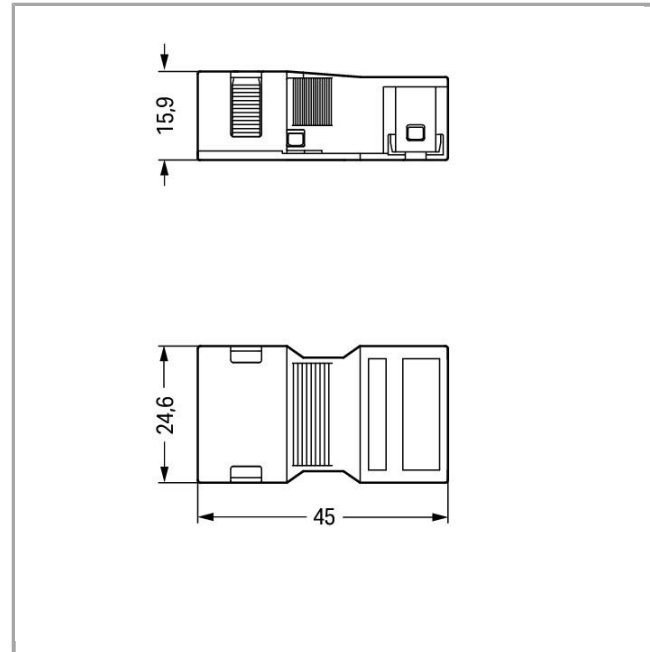

770-502\_041-000

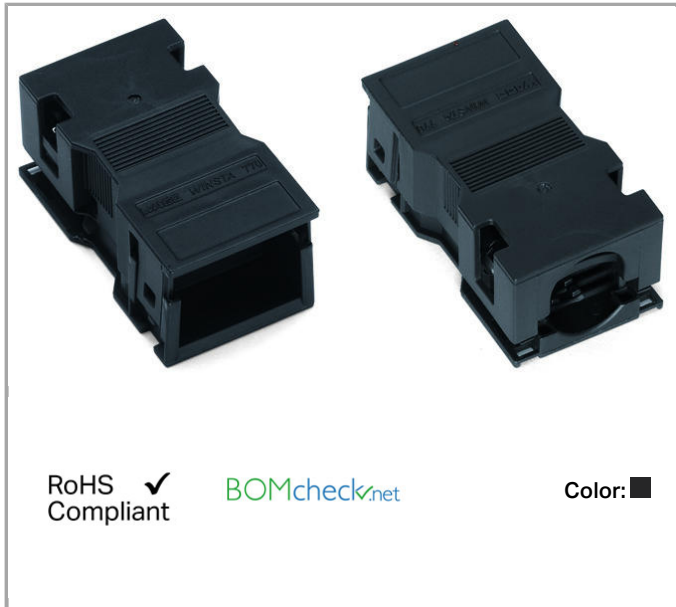

### Data

#### Connection data

Connectable sheathed cable diameter	7 - 10.5 mm
Strip length	35 mm
No. of poles	2

#### Geometrical Data

Width	24.6 mm / 0.969 inch
Height	15.9 mm / 0.626 inch
Depth	45 mm / 1.772 inch

#### Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.192 MJ
Weight	6.39 g

## Environmental Requirements


Processing temperature	-5 +40 °C
Continuous operating temperature	-35 +85 °C
Note on Continuous Service Temperature	Insulating parts for temperatures ≤ 105 °C

## Commercial data


Country of origin	DE
GTIN	4050821137559
Customs Tariff No.	85389099990

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	LR Lloyds Register	IEC 61984	02/20050 (E6)

### Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	LR Lloyds Register	IEC 61984	02/20050 (E6)

## Compatible products

### Marking accessories

Item no.: 210-333 Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive; white	210-333
--	---------

## Downloads

### Documentation

#### Bid Text

770-502/041-000 WINSTA MIDI 2-polig	Apr 4, 2012	doc 24.1 kB	Download
--	-------------	----------------	----------



**CAD/CAE - Smart Data**

**CAD data**

3D Download 770-502/041-000

URL

Download

---

**WSCAD**

WSCAD Universe

Download

---

Subject to changes.

---