



## Data sheet | Item number: 770-513/038-000

Strain relief housing; 3-pole; with locking clip; for 1 cable; 7.0 ... 11.5 mm; 48 mm; white

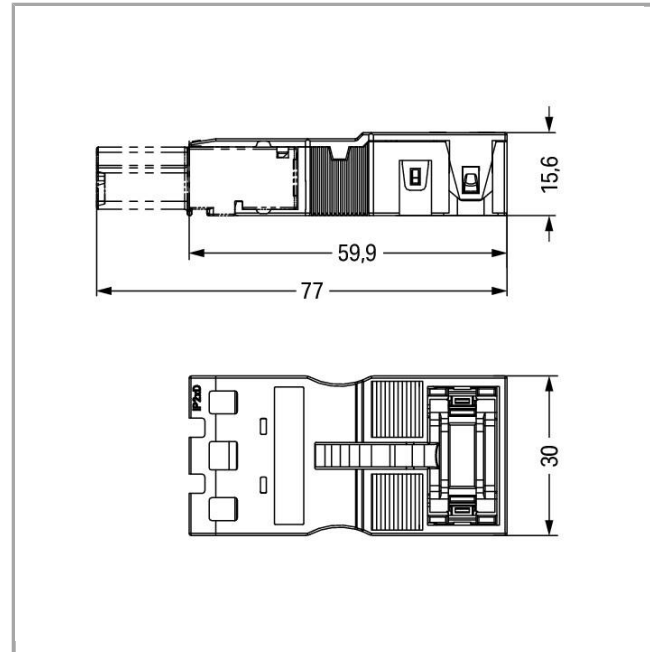

770-513\_038-000

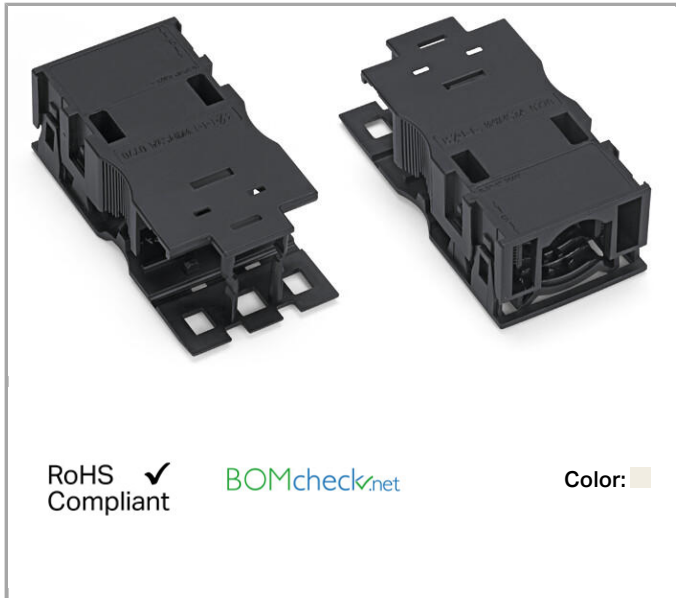

### Data

#### Connection data

Connectable sheathed cable diameter	7 - 11.5 mm
Strip length	48 mm
No. of poles	3

#### Geometrical Data

Width	30 mm / 1.181 inch
Height	15.6 mm / 0.614 inch
Depth	59.6 mm / 2.346 inch

#### Mechanical data

Protection class	IP 2xD
------------------	--------

#### Material Data

Color	white
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.251 MJ

Weight	8.35 g
--------	--------

### Environmental Requirements


Processing temperature	-5 +40 °C
Continuous operating temperature	-35 +85 °C
Note on Continuous Service Temperature	Insulating parts for temperatures ≤ 105 °C

### Commercial data


Country of origin	DE
GTIN	4050821476009
Customs Tariff No.	85389099990

### Approvals / Certificates


#### Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	LR Lloyds Register	IEC 61984	02/20050 (E6)


#### Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	LR Lloyds Register	IEC 61984	02/20050 (E6)

#### Other Approvals

Logo	Approval	Additional Approval Text	Certificate name
	cURus Underwriters Laboratories Inc.	UL 1977	E45171 Sec. 9

#### UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	cURus Underwriters Laboratories Inc.	UL 1977	E45171 Sec. 9



## Compatible products

### Marking accessories

---

Item no.: 210-333

Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive; white

210-333

---

## Downloads

### Documentation

#### Bid Text

770-513/038-000

doc  
24.6 kB

[Download](#)

---

## CAD/CAE - Smart Data

### WSCAD

WSCAD Universe

[Download](#)

---

Subject to changes.

---