


Data sheet | Item number: 770-601

Fixing pin; 6 mm Ø, for 1.0 ... 2.5 mm mounting plates; Plastic

770-601

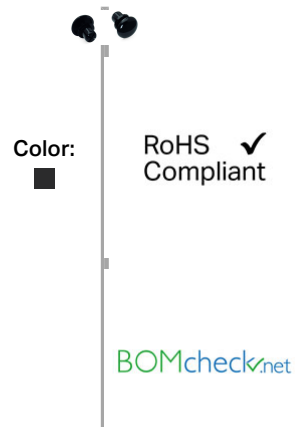

Data

Electrical data

Note on Contact Resistance

approx. 1mΩ contact resistance

approx. 0.25mΩ contact transition plug/socket

Mechanical data

Protection class

IP20

Note on protection class

Only in mated condition with strain relief housing (These compact connectors are not designed for use in open, easily accessible areas.)

Plug connection

Mismating protection

Yes

Locking of plug-in connection

locking lever

Material Data

Color

black

Insulating material

Polyamide 66 (PA 66)

Flammability class per UL94

V0

Contact material

Copper or copper alloy, surface-treated

Weight

0.48 g



Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
Processing temperature	-5 ... +40 °C
Continuous operating temperature	-35 ... +85 °C
Note on Continuous Service Temperature	Insulating parts for temperatures ≤ 105 °C

Commercial data

Product Group	20 (WINSTA)
Country of origin	NL
GTIN	4045454636975
Customs Tariff No.	39269097900

Downloads

Documentation

Bid Text

770-601	Apr 4, 2012	doc	Download
WINSTA Zubehoer		23.0 kB	

Subject to changes.