




RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

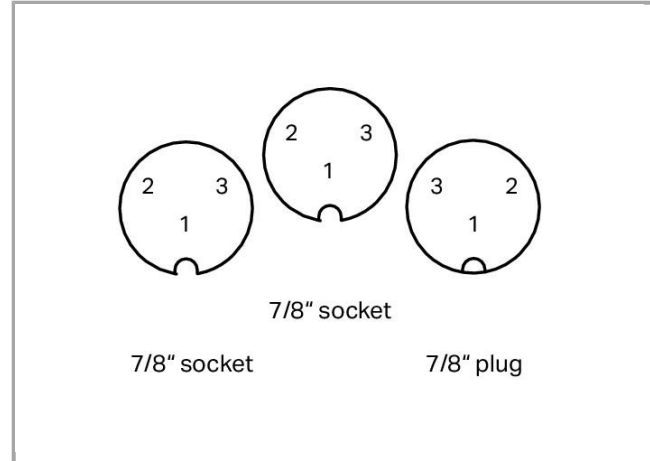

## Item description

### Features:

- 7/8 " screw connection: Industry-prove connection technology for a large selection of different conductors
- High degree of protection for safe field applications
- Vibration- and shock-resistant via integrated locking mechanism
- PUR coating

## Data

### Technical Data

### Operating data

Operating voltage	AC/DC 600 V
Operating current	9 A

### Safety and protection:

Rated impulse voltage	4 kV
-----------------------	------



Protection class	IP67
------------------	------

### Connection data

Connection technology	7/8"; 3-pole; plug
Connection technology 2	2 x 7/8"; 3-pole; socket
Cable diameter	7.4 mm

### Material Data

Weight	97 g
--------	------

### Environmental Requirements

Surrounding air (operating) temperature	-25 80 °C
---	-----------

### Commercial data

Country of origin	DE
GTIN	4055143726863
Customs Tariff No.	85366990990

### Downloads

#### Documentation

##### Bid Text

787-6716/9000-1000 Zubehör, Serie 787	doc 30.2 kB	Download
--	----------------	----------

##### Additional Information

Disposal; Electrical and electronic equipment, Packaging	V 1.0.0	pdf 265.8 kB	Download
--	---------	-----------------	----------

Subject to changes.