


Data sheet | Item number: 787-6716/9310-030

Supply cable, pre-assembled, 7/8 inch; 7/8 inch; 3-pole; Socket, straight;
Length: 3 m



787-6716_9310-030

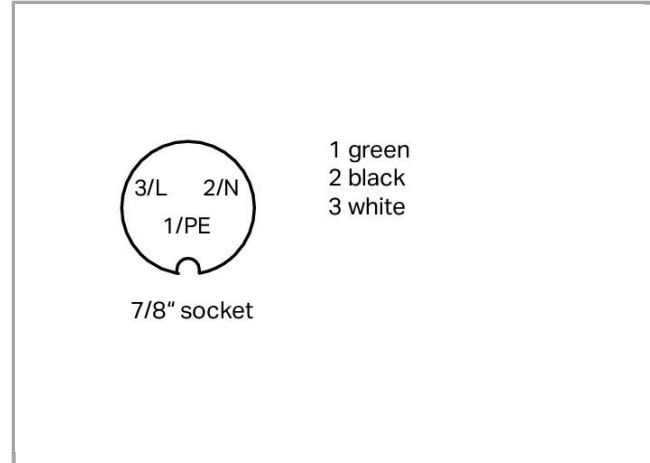

RoHS Compliant [BOMcheck.net](https://www.bomcheck.net)

Item description

Features:

- 7/8 " screw connection: Industry-prove connection technology for a large selection of different conductors
- High degree of protection for safe field applications
- Vibration- and shock-resistant via integrated locking mechanism
- PUR coating

Data

Technical Data

Operating data

Operating voltage	AC/DC 600 V
Operating current	9 A

**Safety and protection:**

Rated impulse voltage	4 kV
Protection class	IP67

Connection data

Connection technology	7/8"; 3-pole; straight socket
Connection technology 2	Open-ended
Cable diameter	7.4 mm

Geometrical Data

Cable length	3 m
--------------	-----

Material Data

Weight	332 g
--------	-------

Environmental Requirements

Surrounding air (operating) temperature	-25 80 °C
---	-----------

Commercial data

Country of origin	DE
GTIN	4055143727020
Customs Tariff No.	85444290900

Downloads**Documentation****Bid Text**

787-6716/9310-030 Zubehör, Serie 787	doc 29.7 kB	Download
---	----------------	----------

Additional Information

Disposal; Electrical and electronic equipment, Packaging	V 1.0.0	pdf 265.8 kB	Download
--	---------	-----------------	----------



Subject to changes.
