



**Data sheet | Item number: 787-6716/9510-050**

Supply cable, pre-assembled, 7/8 inch; 7/8 inch; 5-pole; Plug, straight;  
Length: 5 m

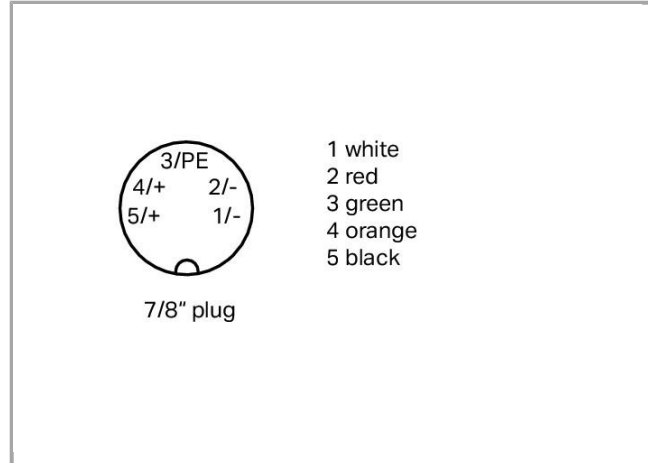

787-6716\_9510-050

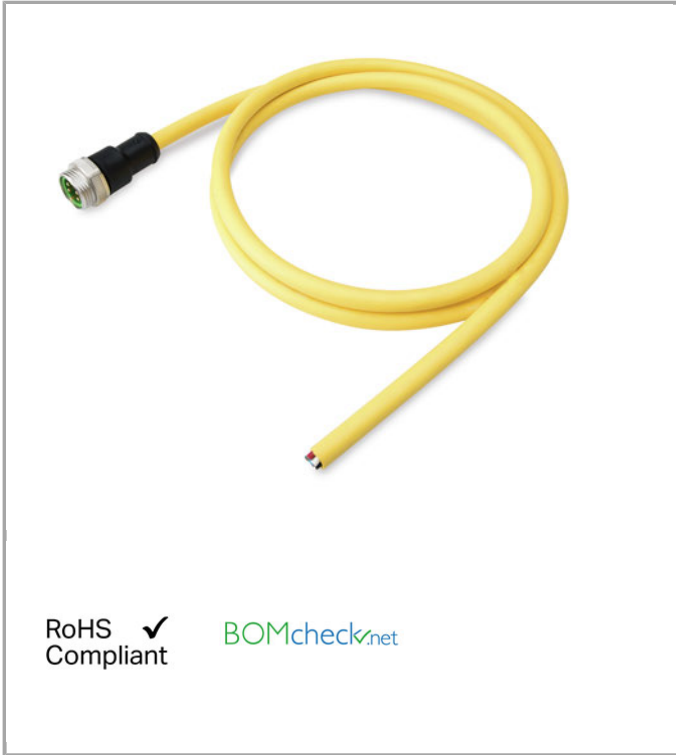

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

**Item description**

**Features:**

- 7/8" screw connection: Industry-prove connection technology for a large selection of different conductors
- High degree of protection for safe field applications
- Vibration- and shock-resistant via integrated locking mechanism
- PUR coating

**Data**

**Technical Data**

**Operating data**

Operating voltage	AC/DC 600 V
Operating current	9 A

**Safety and protection:**

Rated impulse voltage	4 kV
-----------------------	------



Protection class	IP67
------------------	------

---

**Connection data**

Connection technology	7/8"; 5-pole; straight plug
Connection technology 2	Open-ended
Cable diameter	7.4 mm

---

**Geometrical Data**

Cable length	5 m
--------------	-----

---

**Material Data**

Weight	526 g
--------	-------

---

**Environmental Requirements**

Surrounding air (operating) temperature	-25 80 °C
---	-----------

---

**Commercial data**

Country of origin	DE
GTIN	4055143727129
Customs Tariff No.	85444290900

---

**Downloads****Documentation****Bid Text**

787-6716/9510-050	doc	Download
Zubehör, Serie 787	30.7 kB	

---

**Additional Information**

Disposal; Electrical and electronic equipment, Packaging	V 1.0.0	pdf	Download
		265.8 kB	

---

Subject to changes.

---