

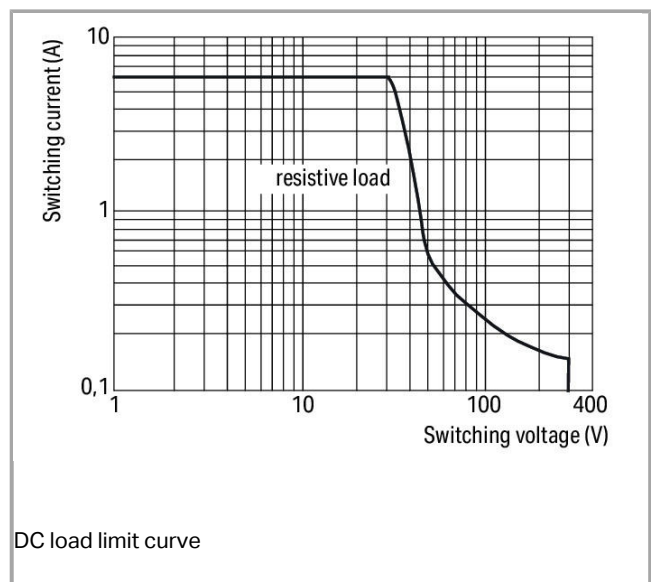
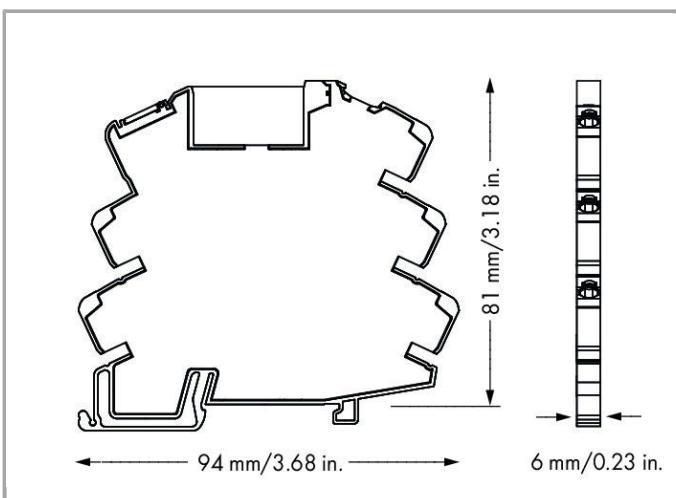


Data sheet | Item number: 857-364

Relay module; Nominal input voltage: 24 V AC/DC; 1 changeover contact;
Limiting continuous current: 6 A; with gold contacts; Yellow status indicator;
Module width: 6 mm

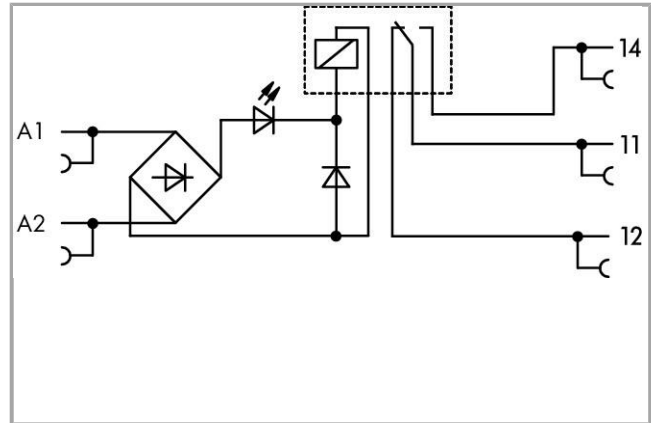

857-364

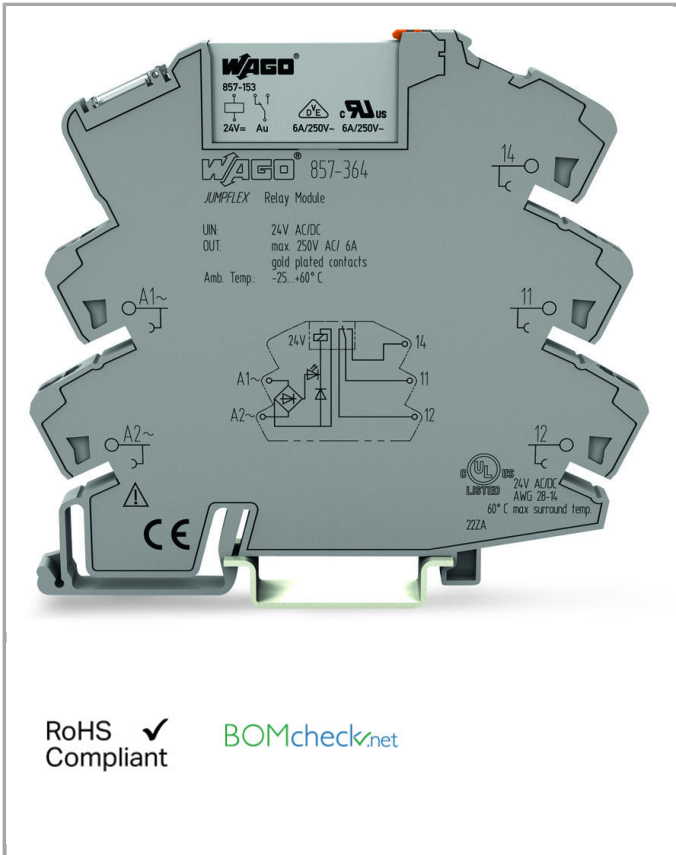

Item description

Note:

- To prevent the gold layer from being damaged, 30 VDC switching voltages and 50 mA currents shall not be exceeded. Higher switching power evaporates the gold layer. The resulting deposits in the housing may reduce the service life.
- Inductive loads have to be attenuated by an appropriate protective circuit in order to protect relay coils and contacts.

Data**Technical Data****Control circuit**

| | |
|--------------------------------|---------------|
| Nominal input voltage U_N | AC/DC 24 V |
| Input voltage range | -15 ... +20 % |
| Nominal input current at U_N | 8.5 mA |

Load circuit:

| | |
|---|---|
| Number of changeover/switchover contacts | 1 |
| Contact material (relay) | AgNi + Au |
| Limiting continuous current | 6 A |
| Max. make current (resistive) | (AC) 20 A / 0.02 s |
| Max. switching voltage | AC 250 V |
| Max. switching power (resistive) | AC 1,500 VA; DC see load limit curve |
| Switching capacity | AC-15: 3 A / AC 250 V; DC-13: 2 A / DC 24 V |
| Recommended minimum load | 1 V / 1 mA / 1 mW |
| Pull-in time (typ.) | 15 ms |
| Drop-out time (typ.) | 25 ms |
| Bounce time (typ.) | 3.5 ms |
| Electrical life (N.O.; resistive load; 23 °C) | 50×10^3 switching operations |
| Mechanical life (N.O.; resistive load; 23 °C) | 5×10^6 switching operations |
| Max. switching load with load/without load | 6 min^{-1} / 180 min^{-1} |

Signaling

| | |
|-------------------|------------|
| Status indication | LED yellow |
|-------------------|------------|

Safety and protection:

| | |
|---|---------|
| Rated voltage | 250 V |
| Rated impulse voltage | 4 kV |
| Pollution degree | 2 |
| Dielectric strength, control/load circuit (AC, 1 min) | 4 kVrms |

| | |
|--|---------|
| Dielectric strength open contact (AC, 1 min) | 1 kVrms |
| Protection class | IP20 |

Connection data

| | |
|-------------------------|--|
| Connection technology | Push-in CAGE CLAMP® |
| Solid conductor | 0.34 ... 2.5 mm ² / 22 ... 14 AWG |
| Fine-stranded conductor | 0.34 ... 2.5 mm ² / 22 ... 14 AWG |
| Strip length | 9 ... 10 mm / 0.35 ... 0.39 inch |

Geometrical Data

| | |
|---------------------------------------|--------------------|
| Width | 6 mm / 0.236 inch |
| Height from upper-edge of DIN-35 rail | 81 mm / 3.189 inch |
| Depth | 94 mm / 3.701 inch |

Mechanical data

| | |
|------------------|-------------|
| Type of mounting | DIN-35 rail |
|------------------|-------------|

Material Data

| | |
|-----------|--------|
| Color | gray |
| Fire load | 0 MJ |
| Weight | 30.3 g |

Environmental Requirements

| | |
|---|----------------|
| Pollution degree | 2 |
| Surrounding air (operating) temperature at U _N | -40 ... 60 °C |
| Surrounding air (storage) temperature | -40 ... 70 °C |
| Processing temperature | -25 ... +50 °C |

Standards and specifications

| | |
|--------------------------|--|
| Standards/specifications | EN 61010-2-201; EN 61810-1; EN 61373; UL 508; ATEX, IEC Ex |
|--------------------------|--|

Elementary relay

| | |
|-----------------------|---------|
| WAGO elementary relay | 857-157 |
|-----------------------|---------|

Commercial data

 


| | |
|-------------------|---------------------------|
| Product Group | 6 (Interface Electronics) |
| Country of origin | DE |
| GTIN | 4045454673505 |

Customs Tariff No.


85364900990

Approvals / Certificates

Ex-Approvals





| Logo | Approval | Additional Approval Text | Certificate name |
|--|---|--------------------------|---------------------|
|  | ATEX DEKRA EXAM GmbH | EN 60079-0 | BVS_14_ATEX_E_091_X |
|  | IECEX DEKRA EXAM GmbH | IEC 60079-0 | IECEX_BVS_14.0079_X |
|  | UL UL International Germany GmbH (HAZARDOUS LOCATIONS) | ANSI/ISA 12.12.01 | E198726 Sec.4 |

















UL-Approvals
















 
| Logo | Approval | Additional Approval Text | Certificate name |
|--|--|--------------------------|------------------|
|  | UL UL International Netherlands B.V. (ORDINARY LOCATIONS) | UL 508 | E175199 Sec.4 |
















Compatible products

















Jumper
















| | | | |
|--|---|----------|---------|
|  | Item no.: 281-482 Comb-style jumper bar; insulated; 2-way; IN = IN terminal block | | 281-482 |
|  | Item no.: 859-402 Push-in type jumper bar; 2-way; Nominal current 18 A; insulated | | 859-402 |
|  | Item no.: 859-402/000-005 Push-in type jumper bar; 2-way; Nominal current 18 A; insulated | /000-005 | 859-402 |
|  | Item no.: 859-402/000-006 Push-in type jumper bar; 2-way; Nominal current 18 A; insulated | /000-006 | 859-402 |
















| | | |
|--|---|---------------------|
|  | Item no.: 859-402/000-029 Push-in type jumper bar; 2-way; Nominal current 18 A; insulated | 859-402 /000-029 |
|  | Item no.: 859-403 Push-in type jumper bar; 3-way; Nominal current 18 A; insulated | 859-403 |
|  | Item no.: 859-403/000-005 Push-in type jumper bar; 3-way; Nominal current 18 A; insulated | 859-403 /000-005 |
|  | Item no.: 859-403/000-006 Push-in type jumper bar; 3-way; Nominal current 18 A; insulated | 859-403 /000-006 |
|  | Item no.: 859-403/000-029 Push-in type jumper bar; 3-way; Nominal current 18 A; insulated | 859-403 /000-029 |
|  | Item no.: 859-404 Push-in type jumper bar; 4-way; Nominal current 18 A; insulated | 859-404 |
|  | Item no.: 859-404/000-005 Push-in type jumper bar; 4-way; Nominal current 18 A; insulated | 859-404 /000-005 |
|  | Item no.: 859-404/000-006 Push-in type jumper bar; 4-way; Nominal current 18 A; insulated | 859-404 /000-006 |
|  | Item no.: 859-404/000-029 Push-in type jumper bar; 4-way; Nominal current 18 A; insulated | 859-404 /000-029 |
|  | Item no.: 859-405 Push-in type jumper bar; 5-way; Nominal current 18 A; insulated | 859-405 |
|  | Item no.: 859-405/000-005 Push-in type jumper bar; 5-way; Nominal current 18 A; insulated | 859-405 /000-005 |
|  | Item no.: 859-405/000-006 Push-in type jumper bar; 5-way; Nominal current 18 A; insulated | 859-405 /000-006 |
|  | Item no.: 859-405/000-029 Push-in type jumper bar; 5-way; Nominal current 18 A; insulated | 859-405 /000-029 |
|  | Item no.: 859-406 Push-in type jumper bar; 6-way; Nominal current 18 A; insulated | 859-406 |
|  | Item no.: 859-406/000-005 Push-in type jumper bar; 6-way; Nominal current 18 A; insulated | 859-406 /000-005 |
|  | Item no.: 859-406/000-006 Push-in type jumper bar; 6-way; Nominal current 18 A; insulated | 859-406 /000-006 |
















| | | | |
|--|--|----------|---------|
|  | Item no.: 859-406/000-029 Push-in type jumper bar; 6-way; Nominal current 18 A; insulated | /000-029 | 859-406 |
|  | Item no.: 859-407 Push-in type jumper bar; 7-way; Nominal current 18 A; insulated | | 859-407 |
|  | Item no.: 859-407/000-005 Push-in type jumper bar; 7-way; Nominal current 18 A; insulated | /000-005 | 859-407 |
|  | Item no.: 859-407/000-006 Push-in type jumper bar; 7-way; Nominal current 18 A; insulated | /000-006 | 859-407 |
|  | Item no.: 859-407/000-029 Push-in type jumper bar; 7-way; Nominal current 18 A; insulated | /000-029 | 859-407 |
|  | Item no.: 859-408 Push-in type jumper bar; 8-way; Nominal current 18 A; insulated | | 859-408 |
|  | Item no.: 859-408/000-005 Push-in type jumper bar; 8-way; Nominal current 18 A; insulated | /000-005 | 859-408 |
|  | Item no.: 859-408/000-006 Push-in type jumper bar; 8-way; Nominal current 18 A; insulated | /000-006 | 859-408 |
|  | Item no.: 859-408/000-029 Push-in type jumper bar; 8-way; Nominal current 18 A; insulated | /000-029 | 859-408 |
|  | Item no.: 859-409 Push-in type jumper bar; 9-way; Nominal current 18 A; insulated | | 859-409 |
|  | Item no.: 859-409/000-005 Push-in type jumper bar; 9-way; Nominal current 18 A; insulated | /000-005 | 859-409 |
|  | Item no.: 859-409/000-006 Push-in type jumper bar; 9-way; Nominal current 18 A; insulated | /000-006 | 859-409 |
|  | Item no.: 859-409/000-029 Push-in type jumper bar; 9-way; Nominal current 18 A; insulated | /000-029 | 859-409 |
|  | Item no.: 859-410 Push-in type jumper bar; 10-way; Nominal current 18 A; insulated | | 859-410 |
|  | Item no.: 859-410/000-005 Push-in type jumper bar; 10-way; Nominal current 18 A; insulated | /000-005 | 859-410 |
|  | Item no.: 859-410/000-006 Push-in type jumper bar; 10-way; Nominal current 18 A; insulated | /000-006 | 859-410 |












| | | |
|--|--|----------------------|
|  | Item no.: 859-410/000-029 Push-in type jumper bar; 10-way; Nominal current 18 A; insulated | 859-410 /000-029 |
| tools | | |
|  | Item no.: 210-720 Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm | 210-720 |
| General accessories | | |
|  | Item no.: 209-184 Protection cover | 209-184 |
|  | Item no.: 249-105 Group marker carrier | 249-105 |
|  | Item no.: 857-153 Basic relay; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 6 A; with gold contacts; Module width: 5 mm; Module height: 15 mm | 857-153 |
| Marking accessories | | |
|  | Item no.: 2009-110 Marking strips; on reel; not stretchable; plain; snap-on type | 2009-110 |
|  | Item no.: 2009-115 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 |
|  | Item no.: 2009-115/000-002 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-002 |
|  | Item no.: 2009-115/000-006 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-006 |
|  | Item no.: 2009-115/000-007 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-007 |
|  | Item no.: 2009-115/000-012 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-012 |
|  | Item no.: 2009-115/000-017 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-017 |
|  | Item no.: 2009-115/000-023 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-023 |
|  | Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | 2009-115 /000-024 |
|  | Item no.: 209-128 Adaptor | 209-128 |

| | | |
|--|--|---------------------|
|  | Item no.: 209-183 Marker card | 209-183 |
|  | Item no.: 210-110 Fiber-tip pen | 210-110 |
|  | Item no.: 793-501 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 |
|  | Item no.: 793-501/000-002 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-002 |
|  | Item no.: 793-501/000-005 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-005 |
|  | Item no.: 793-501/000-006 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-006 |
|  | Item no.: 793-501/000-007 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-007 |
|  | Item no.: 793-501/000-012 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-012 |
|  | Item no.: 793-501/000-017 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-017 |
|  | Item no.: 793-501/000-023 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-023 |
|  | Item no.: 793-501/000-024 WMB marking card; as card; not stretchable; plain; snap-on type | 793-501 /000-024 |
|  | Item no.: 793-502 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | 793-502 |
|  | Item no.: 793-502/000-002 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | 793-502 /000-002 |
|  | Item no.: 793-502/000-005 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | 793-502 /000-005 |
|  | Item no.: 793-502/000-006 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | 793-502 /000-006 |
|  | Item no.: 793-502/000-007 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | 793-502 /000-007 |

| | | | |
|--|---|----------|---------|
|  | Item no.: 793-502/000-012 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | /000-012 | 793-502 |
|  | Item no.: 793-502/000-017 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | /000-017 | 793-502 |
|  | Item no.: 793-502/000-023 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | /000-023 | 793-502 |
|  | Item no.: 793-502/000-024 WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type | /000-024 | 793-502 |
|  | Item no.: 793-503 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | | 793-503 |
|  | Item no.: 793-503/000-002 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-002 | 793-503 |
|  | Item no.: 793-503/000-005 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-005 | 793-503 |
|  | Item no.: 793-503/000-006 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-006 | 793-503 |
|  | Item no.: 793-503/000-007 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-007 | 793-503 |
|  | Item no.: 793-503/000-012 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-012 | 793-503 |
|  | Item no.: 793-503/000-017 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-017 | 793-503 |
|  | Item no.: 793-503/000-023 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-023 | 793-503 |
|  | Item no.: 793-503/000-024 WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type | /000-024 | 793-503 |
|  | Item no.: 793-504 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type | | 793-504 |
|  | Item no.: 793-504/000-002 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type | /000-002 | 793-504 |

| | | |
|--|---|---------|
|  | Item no.: 793-504/000-005 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type / 000-005 | 793-504 |
|  | Item no.: 793-504/000-006 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type / 000-006 | 793-504 |
|  | Item no.: 793-504/000-012 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type / 000-012 | 793-504 |
|  | Item no.: 793-504/000-017 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type / 000-017 | 793-504 |
|  | Item no.: 793-504/000-023 WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type / 000-023 | 793-504 |
|  | Item no.: 793-505 WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type | 793-505 |
|  | Item no.: 793-505/000-005 WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type / 000-005 | 793-505 |
|  | Item no.: 793-505/000-006 WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type / 000-006 | 793-505 |
|  | Item no.: 793-505/000-007 WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type / 000-007 | 793-505 |
|  | Item no.: 793-505/000-012 WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type / 000-012 | 793-505 |
|  | Item no.: 793-506 WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type | 793-506 |
|  | Item no.: 793-506/000-005 WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type / 000-005 | 793-506 |
|  | Item no.: 793-506/000-006 WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type / 000-006 | 793-506 |
|  | Item no.: 793-506/000-012 WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type / 000-012 | 793-506 |
|  | Item no.: 793-506/000-017 WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type / 000-017 | 793-506 |
| | Item no.: 793-5501 | |

| | | | |
|--|---|----------|----------|
|  | WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type | | 793-5501 |
|  | Item no.: 793-5501/000-002 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type | /000-002 | 793-5501 |
|  | Item no.: 793-5501/000-005 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-005 | 793-5501 |
|  | Item no.: 793-5501/000-006 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-006 | 793-5501 |
|  | Item no.: 793-5501/000-007 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-007 | 793-5501 |
|  | Item no.: 793-5501/000-012 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-012 | 793-5501 |
|  | Item no.: 793-5501/000-014 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-014 | 793-5501 |
|  | Item no.: 793-5501/000-017 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-017 | 793-5501 |
|  | Item no.: 793-5501/000-023 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-023 | 793-5501 |
|  | Item no.: 793-5501/000-024 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type | /000-024 | 793-5501 |
|  | Item no.: 793-566 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | | 793-566 |
|  | Item no.: 793-566/000-002 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | /000-002 | 793-566 |
|  | Item no.: 793-566/000-005 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | /000-005 | 793-566 |
|  | Item no.: 793-566/000-006 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | /000-006 | 793-566 |
|  | Item no.: 793-566/000-007 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | /000-007 | 793-566 |

| | | |
|--|--|---------------------|
|  | Item no.: 793-566/000-012 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | 793-566 /000-012 |
|  | Item no.: 793-566/000-017 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | 793-566 /000-017 |
|  | Item no.: 793-566/000-023 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | 793-566 /000-023 |
|  | Item no.: 793-566/000-024 WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type | 793-566 /000-024 |
| transfer module | | |
|  | Item no.: 857-981 Interface adapter; 14-pole; High-side switching input | 857-981 |
|  | Item no.: 857-982 Interface adapter; 14-pole; High-side switching output | 857-982 |
|  | Item no.: 857-986 Interface adapter; 15-pole; High-side switching input | 857-986 |
| ferrule | | |
|  | Item no.: 216-241 Ferrule; Sleeve for 0.5 mm ² / 20 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | 216-241 |
|  | Item no.: 216-242 Ferrule; Sleeve for 0.75 mm ² / 18 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | 216-242 |
|  | Item no.: 216-243 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | 216-243 |
|  | Item no.: 216-244 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | 216-244 |

Downloads

Documentation

Bid Text

| | | | |
|----------------|--------------|----------------|----------|
| 857-364 | Jan 15, 2016 | doc 27.6 kB | Download |
| Relaisbaustein | | | |

Instruction Leaflet

| | | |
|--|---------------|----------|
| Relay Socket with pluggable small switching Relay | pdf 2.4 MB | Download |
| 1 changeover contact Input nominal voltage AC/DC 24 V, Gold contacts | | |

Additional Information



Disposal; Electrical and electronic equipment, Packaging

V 1.0.0

pdf
265.8 kB

[Download](#)

CAD/CAE - Smart Data

CAD data

3D Download 857-364

[URL](#)

[Download](#)

Step file 857-03xx Series

1.0
Jun 30, 2011

STP
299.3 kB

[Download](#)

Subject to changes.
