



Data sheet | Item number: 870-107

2-conductor/2-pin, double-deck carrier terminal block; 2-conductor/2-pin ground terminal block; PE; internal commoning; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; CAGE CLAMP®

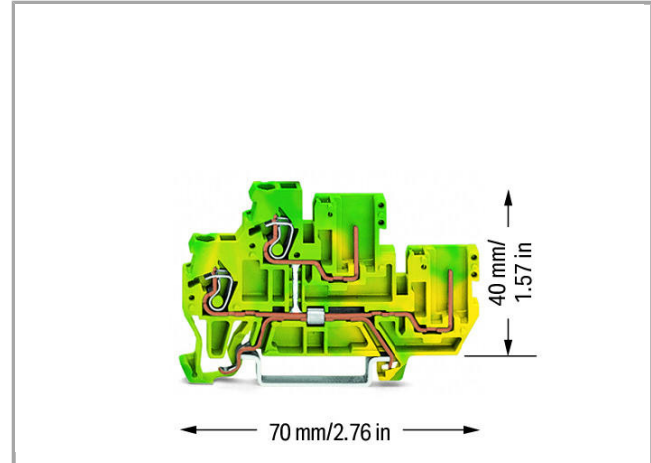

870-107

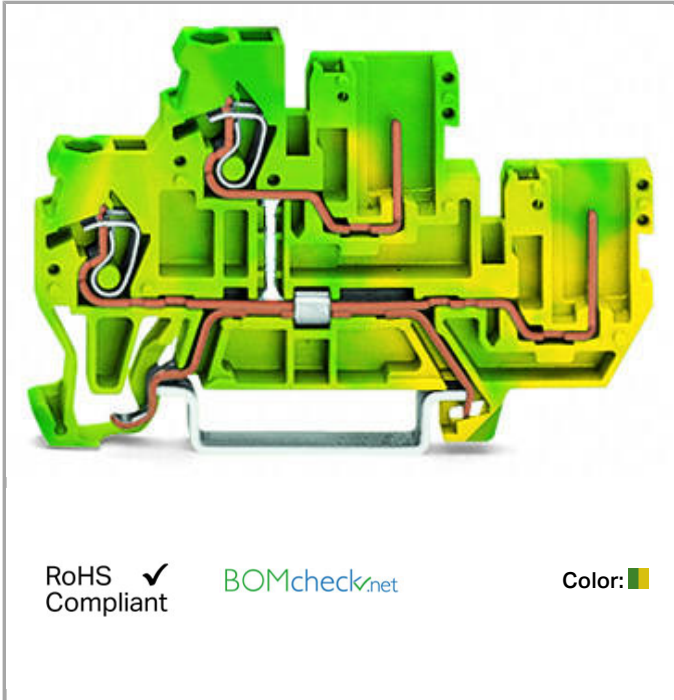

Item description

Safety information 1:

Max. insulation diameter: 4.4 mm

Data

Connection data

Connection technology	CAGE CLAMP®
Actuation type	Open Tool Slot
Connectable conductor materials	Copper
Solid conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length	6 ... 7 mm / 0.24 ... 0.28 inch
Total number of connection points	2
Total number of potentials	1
Number of levels	2
Type of wiring	Front-entry wiring

Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	40 mm / 1.575 inch
Depth	70 mm / 2.756 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Potential marking	PE
Marking level	Side marking

Material Data

Color	green-yellow
Fire load	0.165 MJ
Weight	11 g

Commercial data


Country of origin	DE
GTIN	4045454225346
Customs Tariff No.	85366990990

Approvals / Certificates

Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 60947	NTR NL 7468
	CCA DEKRA Certification B.V.	EN 60947	2189801.01

Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	ABS American Bureau of Shipping	-	14- HG1293677- PDA




LR
Lloyds Register

EN 60947








91/20112
(E9)

















UL-Approvals















Logo	Approval	Additional Approval Text	Certificate name
	cURus UL International Germany GmbH	UL 1059	20160928- E45172

Compatible products

General accessories

	Item no.: 769-438 Pin cover; with marker slot for miniature WSB		769-438
	Item no.: 769-439 Pin cover; with marker slot for miniature WSB		769-439
	Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole		769-501
	Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole	/000-006	769-501
	Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	/000-016	769-501
	Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole		769-502
	Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	/000-006	769-502

	Item no.: 769-502/000-016 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	769-502
		/UUU-U16
	Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503
	Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503
		/UUU-U06
	Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm ² ; 1-pole	769-503
		/UUU-U16
	Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	769-512
	Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	769-512
		/UUU-U06
	Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	769-512
		/UUU-U16
	Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	769-513
	Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole	769-513
		/UUU-U06
	Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole	769-513
		/UUU-U16
	Item no.: 769-515 1-conductor end module; angled; codable; 1-pole	769-515
	Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole	769-515
		/UUU-U06
	Item no.: 769-515/000-016 1-conductor end module; angled; codable; 1-pole	769-515
		/UUU-U16
	Item no.: 870-182 Adaptor	870-182
	Item no.: 870-183 Adaptor	870-183
	Item no.: 870-184 Adaptor	870-184
	Item no.: 870-425 Tap-off module; with anti-rotation protection; modular; suitable for 870 Series terminal blocks with	870-425

	jumper slots in the current bar	
	Item no.: 870-426 Tap-off module; modular; suitable for 870 Series terminal blocks with jumper slots in the current bar	870-426
	Item no.: 870-427 Spacer module; modular; bridging commoned terminal blocks	870-427
Jumper		
	Item no.: 210-103 Wire commoning chain; insulated; 50 connections	210-103
	Item no.: 709-110 Wire commoning chain; insulated; 4 connections; 3 x 110 mm	709-110
	Item no.: 709-111 Wire commoning chain; insulated; 3 connections; 2 x 120 mm	709-111
	Item no.: 709-112 Wire commoning chain; insulated; 3 connections; 2 x 170 mm	709-112
	Item no.: 870-402 Push-in type jumper bar; insulated; 2-way; Nominal current 18 A	870-402
	Item no.: 870-403 Push-in type jumper bar; insulated; 3-way; Nominal current 18 A	870-403
	Item no.: 870-404 Push-in type jumper bar; insulated; 4-way; Nominal current 18 A	870-404
	Item no.: 870-405 Push-in type jumper bar; insulated; 5-way; Nominal current 18 A	870-405
	Item no.: 870-405/011-000 Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A	870-405 /011-000
	Item no.: 870-406 Push-in type jumper bar; insulated; 6-way; Nominal current 18 A	870-406
	Item no.: 870-407 Push-in type jumper bar; insulated; 7-way; Nominal current 18 A	870-407
	Item no.: 870-407/011-000 Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A	870-407 /011-000
	Item no.: 870-408 Push-in type jumper bar; insulated; 8-way; Nominal current 18 A	870-408
	Item no.: 870-409 Push-in type jumper bar; insulated; 9-way; Nominal current 18 A	870-409
	Item no.: 870-409/011-000 Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A	870-409 /011-000
	Item no.: 870-410	

Push-in type jumper bar; insulated; 10-way; Nominal current 18 A

870-410

**Item no.: 870-433**

Push-in type jumper bar; insulated; from 1 to 3; Nominal current 18 A

870-433

**Item no.: 870-434**

Push-in type jumper bar; insulated; from 1 to 4; Nominal current 18 A

870-434

**Item no.: 870-435**

Push-in type jumper bar; insulated; from 1 to 5; Nominal current 18 A

870-435

Item no.: 870-440

Push-in type jumper bar; insulated; from 1 to 10; Nominal current 18 A

870-440

Female plug**Item no.: 769-101**1-conductor female plug; 4 mm²; 1-pole

769-101

**Item no.: 769-101/000-006**1-conductor female plug; 4 mm²; 1-pole

769-101

/000-006

**Item no.: 769-101/000-016**1-conductor female plug; 4 mm²; 1-pole

769-101

/000-016

**Item no.: 769-101/022-000**1-conductor female plug; angled; 4 mm²; 1-pole

769-101

/022-000

**Item no.: 769-101/022-016**1-conductor female plug; angled; 4 mm²; 1-pole

769-101

/022-016

**Item no.: 769-102**1-conductor female plug; 4 mm²; 2-pole

769-102

**Item no.: 769-102/000-006**1-conductor female plug; 4 mm²; 2-pole

769-102

/000-006

**Item no.: 769-102/000-036**1-conductor female plug; 4 mm²; 2-pole

769-102

/000-036

**Item no.: 769-102/000-037**1-conductor female plug; 4 mm²; 2-pole

769-102

/000-037

**Item no.: 769-102/022-000**1-conductor female plug; angled; 4 mm²; 2-pole

769-102

/022-000



 
 


 



 



 
**Item no.: 769-103**1-conductor female plug; 4 mm²; 3-pole









 






769-103







 


 
 


 
 
**Item no.: 769-103/000-006**1-conductor female plug; 4 mm²; 3-pole







 




 

 
 
769-103







 








/000-006

	Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole	/000-036	769-103
	Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole	/000-037	769-103
	Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole	/000-038	769-103
	Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole	/000-039	769-103
	Item no.: 769-103/022-000 1-conductor female plug; angled; 4 mm ² ; 3-pole	/022-000	769-103
	Item no.: 769-104 1-conductor female plug; 4 mm ² ; 4-pole		769-104
	Item no.: 769-104/000-006 1-conductor female plug; 4 mm ² ; 4-pole	/000-006	769-104
	Item no.: 769-104/000-036 1-conductor female plug; 4 mm ² ; 4-pole	/000-036	769-104
	Item no.: 769-104/000-037 1-conductor female plug; 4 mm ² ; 4-pole	/000-037	769-104
	Item no.: 769-104/000-038 1-conductor female plug; 4 mm ² ; 4-pole	/000-038	769-104
	Item no.: 769-104/000-039 1-conductor female plug; 4 mm ² ; 4-pole	/000-039	769-104
	Item no.: 769-104/022-000 1-conductor female plug; angled; 4 mm ² ; 4-pole	/022-000	769-104
	Item no.: 769-105 1-conductor female plug; 4 mm ² ; 5-pole		769-105
	Item no.: 769-105/000-006 1-conductor female plug; 4 mm ² ; 5-pole	/000-006	769-105
	Item no.: 769-105/000-036 1-conductor female plug; 4 mm ² ; 5-pole	/000-036	769-105

	Item no.: 769-105/000-037 1-conductor female plug; 4 mm ² ; 5-pole	/000-037	769-105
	Item no.: 769-105/000-038 1-conductor female plug; 4 mm ² ; 5-pole	/000-038	769-105
	Item no.: 769-105/000-039 1-conductor female plug; 4 mm ² ; 5-pole	/000-039	769-105
	Item no.: 769-105/022-000 1-conductor female plug; angled; 4 mm ² ; 5-pole	/022-000	769-105
	Item no.: 769-106 1-conductor female plug; 4 mm ² ; 6-pole		769-106
	Item no.: 769-106/000-006 1-conductor female plug; 4 mm ² ; 6-pole	/000-006	769-106
	Item no.: 769-106/000-036 1-conductor female plug; 4 mm ² ; 6-pole	/000-036	769-106
	Item no.: 769-106/000-037 1-conductor female plug; 4 mm ² ; 6-pole	/000-037	769-106
	Item no.: 769-106/000-038 1-conductor female plug; 4 mm ² ; 6-pole	/000-038	769-106
	Item no.: 769-106/000-039 1-conductor female plug; 4 mm ² ; 6-pole	/000-039	769-106
	Item no.: 769-106/022-000 1-conductor female plug; angled; 4 mm ² ; 6-pole	/022-000	769-106
	Item no.: 769-107 1-conductor female plug; 4 mm ² ; 7-pole		769-107
	Item no.: 769-107/000-006 1-conductor female plug; 4 mm ² ; 7-pole	/000-006	769-107
	Item no.: 769-107/000-036 1-conductor female plug; 4 mm ² ; 7-pole	/000-036	769-107
	Item no.: 769-107/000-037 1-conductor female plug; 4 mm ² ; 7-pole	/000-037	769-107

	Item no.: 769-107/000-038 1-conductor female plug; 4 mm ² ; 7-pole	/000-038	769-107
	Item no.: 769-107/000-039 1-conductor female plug; 4 mm ² ; 7-pole	/000-039	769-107
	Item no.: 769-107/022-000 1-conductor female plug; angled; 4 mm ² ; 7-pole	/022-000	769-107
	Item no.: 769-108 1-conductor female plug; 4 mm ² ; 8-pole		769-108
	Item no.: 769-108/000-006 1-conductor female plug; 4 mm ² ; 8-pole	/000-006	769-108
	Item no.: 769-108/000-036 1-conductor female plug; 4 mm ² ; 8-pole	/000-036	769-108
	Item no.: 769-108/000-037 1-conductor female plug; 4 mm ² ; 8-pole	/000-037	769-108
	Item no.: 769-108/000-038 1-conductor female plug; 4 mm ² ; 8-pole	/000-038	769-108
	Item no.: 769-108/000-039 1-conductor female plug; 4 mm ² ; 8-pole	/000-039	769-108
	Item no.: 769-108/022-000 1-conductor female plug; angled; 4 mm ² ; 8-pole	/022-000	769-108
	Item no.: 769-109 1-conductor female plug; 4 mm ² ; 9-pole		769-109
	Item no.: 769-109/000-006 1-conductor female plug; 4 mm ² ; 9-pole	/000-006	769-109
	Item no.: 769-109/000-036 1-conductor female plug; 4 mm ² ; 9-pole	/000-036	769-109
	Item no.: 769-109/000-037 1-conductor female plug; 4 mm ² ; 9-pole	/000-037	769-109
	Item no.: 769-109/000-038 1-conductor female plug; 4 mm ² ; 9-pole	/000-038	769-109

	Item no.: 769-109/000-039 1-conductor female plug; 4 mm ² ; 9-pole		769-109
		/000-039	
	Item no.: 769-109/022-000 1-conductor female plug; angled; 4 mm ² ; 9-pole		769-109
		/022-000	
	Item no.: 769-110 1-conductor female plug; 4 mm ² ; 10-pole		769-110
	Item no.: 769-110/000-006 1-conductor female plug; 4 mm ² ; 10-pole		769-110
		/000-006	
	Item no.: 769-110/000-036 1-conductor female plug; 4 mm ² ; 10-pole		769-110
		/000-036	
	Item no.: 769-110/000-037 1-conductor female plug; 4 mm ² ; 10-pole		769-110
		/000-037	
	Item no.: 769-110/000-038 1-conductor female plug; 4 mm ² ; 10-pole		769-110
		/000-038	
	Item no.: 769-110/000-039 1-conductor female plug; 4 mm ² ; 10-pole		769-110
		/000-039	
	Item no.: 769-110/022-000 1-conductor female plug; angled; 4 mm ² ; 10-pole		769-110
		/022-000	
	Item no.: 769-111 1-conductor female plug; 4 mm ² ; 11-pole		769-111
	Item no.: 769-111/000-006 1-conductor female plug; 4 mm ² ; 11-pole		769-111
		/000-006	
	Item no.: 769-111/000-036 1-conductor female plug; 4 mm ² ; 11-pole		769-111
		/000-036	
	Item no.: 769-111/000-037 1-conductor female plug; 4 mm ² ; 11-pole		769-111
		/000-037	
	Item no.: 769-111/000-038 1-conductor female plug; 4 mm ² ; 11-pole		769-111
		/000-038	
	Item no.: 769-111/000-039 1-conductor female plug; 4 mm ² ; 11-pole		769-111
		/000-039	

	Item no.: 769-111/022-000 1-conductor female plug; angled; 4 mm ² ; 11-pole	769-111 /022-000
	Item no.: 769-112 1-conductor female plug; 4 mm ² ; 12-pole	769-112
	Item no.: 769-112/000-006 1-conductor female plug; 4 mm ² ; 12-pole	769-112 /000-006
	Item no.: 769-112/000-036 1-conductor female plug; 4 mm ² ; 12-pole	769-112 /000-036
	Item no.: 769-112/000-037 1-conductor female plug; 4 mm ² ; 12-pole	769-112 /000-037
	Item no.: 769-112/000-038 1-conductor female plug; 4 mm ² ; 12-pole	769-112 /000-038
	Item no.: 769-112/000-039 1-conductor female plug; 4 mm ² ; 12-pole	769-112 /000-039
	Item no.: 769-112/022-000 1-conductor female plug; angled; 4 mm ² ; 12-pole	769-112 /022-000
	Item no.: 769-113 1-conductor female plug; 4 mm ² ; 13-pole	769-113
	Item no.: 769-113/000-036 1-conductor female plug; 4 mm ² ; 13-pole	769-113 /000-036
	Item no.: 769-113/000-037 1-conductor female plug; 4 mm ² ; 13-pole	769-113 /000-037
	Item no.: 769-113/000-038 1-conductor female plug; 4 mm ² ; 13-pole	769-113 /000-038
	Item no.: 769-113/000-039 1-conductor female plug; 4 mm ² ; 13-pole	769-113 /000-039
	Item no.: 769-113/022-000 1-conductor female plug; angled; 4 mm ² ; 13-pole	769-113 /022-000
	Item no.: 769-114 1-conductor female plug; 4 mm ² ; 14-pole	769-114
	Item no.: 769-114/000-006 1-conductor female plug; 4 mm ² ; 14-pole	769-114 /000-006



Item no.: 769-114/000-036
1-conductor female plug; 4 mm²; 14-pole

/000-036

769-114



Item no.: 769-114/000-037
1-conductor female plug; 4 mm²; 14-pole

/000-037

769-114



Item no.: 769-114/000-038
1-conductor female plug; 4 mm²; 14-pole

/000-038

769-114



Item no.: 769-114/000-039
1-conductor female plug; 4 mm²; 14-pole

/000-039

769-114



Item no.: 769-114/022-000
1-conductor female plug; angled; 4 mm²; 14-pole

/022-000

769-114



Item no.: 769-115
1-conductor female plug; 4 mm²; 15-pole

769-115



Item no.: 769-115/000-036
1-conductor female plug; 4 mm²; 15-pole

/000-036

769-115



Item no.: 769-115/000-037
1-conductor female plug; 4 mm²; 15-pole

/000-037

769-115



Item no.: 769-115/000-038
1-conductor female plug; 4 mm²; 15-pole

/000-038

769-115



Item no.: 769-115/000-039
1-conductor female plug; 4 mm²; 15-pole

/000-039

769-115



Item no.: 769-115/022-000
1-conductor female plug; angled; 4 mm²; 15-pole

/022-000

769-115

assembling



Item no.: 209-106
Mounting carrier; for isolated mounting on DIN 35 rails

209-106

Insulation stop




















Item no.: 280-470
Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 5 pieces/strip
















280-470
































Item no.: 280-471
Insulation stop; 0.25 - 0.5 mm²; 5 pieces/strip


 



 



 


280-471

	Item no.: 280-472 Insulation stop; 0.75 - 1 mm ² ; 5 pieces/strip	280-472
Coding		
	Item no.: 769-435 Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors	769-435
ferrule		
	Item no.: 216-121 Ferrule; Sleeve for 0.5 mm ² / AWG 22; uninsulated; electro-tin plated	216-121
	Item no.: 216-122 Ferrule; Sleeve for 0.75 mm ² / AWG 20; uninsulated; electro-tin plated	216-122
	Item no.: 216-123 Ferrule; Sleeve for 1 mm ² / AWG 18; uninsulated; electro-tin plated	216-123
	Item no.: 216-124 Ferrule; Sleeve for 1.5 mm ² / AWG 16; uninsulated; electro-tin plated	216-124
	Item no.: 216-131 Ferrule; Sleeve for 0.25 mm ² / AWG 24; uninsulated; electro-tin plated	216-131
	Item no.: 216-132 Ferrule; Sleeve for 0.34 mm ² / AWG 24; uninsulated; electro-tin plated	216-132
	Item no.: 216-221 Ferrule; Sleeve for 0.5 mm ² / 20 AWG; insulated; electro-tin plated	216-221
	Item no.: 216-222 Ferrule; Sleeve for 0.75 mm ² / 18 AWG; insulated; electro-tin plated	216-222
	Item no.: 216-223 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated	216-223
	Item no.: 216-224 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated	216-224
	Item no.: 216-321 Ferrule; Sleeve for 0.25 mm ² / AWG 24; insulated; electro-tin plated	216-321
	Item no.: 216-322 Ferrule; Sleeve for 0.34 mm ² / 22 AWG; insulated; electro-tin plated	216-322
End plate		
	Item no.: 870-118 End and intermediate plate; 1 mm thick	870-118
	Item no.: 870-119 End and intermediate plate; 1 mm thick	870-119
Marking accessories		
	Item no.: 2009-115 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115
	Item no.: 2009-115/000-002 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	2009-115 /UUU-UUZ

	Item no.: 2009-115/000-006 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-006	2009-115
	Item no.: 2009-115/000-007 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-007	2009-115
	Item no.: 2009-115/000-012 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-012	2009-115
	Item no.: 2009-115/000-017 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-017	2009-115
	Item no.: 2009-115/000-023 WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-023	2009-115
	Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-024	2009-115
	Item no.: 2009-145 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type		2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-002	2009-145
	Item no.: 2009-145/000-005 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-005	2009-145
	Item no.: 2009-145/000-006 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-006	2009-145
	Item no.: 2009-145/000-007 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-007	2009-145
	Item no.: 2009-145/000-012 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-012	2009-145
	Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-023	2009-145
	Item no.: 2009-145/000-024 Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	/000-024	2009-145
	Item no.: 2009-198 Adaptor		2009-198

	Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card	248-501
	Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-002
	Item no.: 248-501/000-005 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-005
	Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-006
	Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-007
	Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-012
	Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-017
	Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-023
	Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	248-501 /000-024
	Item no.: 793-501 WMB marking card; as card; not stretchable; plain; snap-on type	793-501
	Item no.: 793-501/000-002 WMB marking card; as card; not stretchable; plain; snap-on type	793-501 /000-002
	Item no.: 793-501/000-005 WMB marking card; as card; not stretchable; plain; snap-on type	793-501 /000-005
	Item no.: 793-501/000-006 WMB marking card; as card; not stretchable; plain; snap-on type	793-501 /000-006
	Item no.: 793-501/000-007 WMB marking card; as card; not stretchable; plain; snap-on type	793-501 /000-007
	Item no.: 793-501/000-012 WMB marking card; as card; not stretchable; plain; snap-on type	793-501 /000-012

	Item no.: 793-501/000-017 WMB marking card; as card; not stretchable; plain; snap-on type	/000-017	793-501
	Item no.: 793-501/000-023 WMB marking card; as card; not stretchable; plain; snap-on type	/000-023	793-501
	Item no.: 793-501/000-024 WMB marking card; as card; not stretchable; plain; snap-on type	/000-024	793-501
	Item no.: 793-5501 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type		793-5501
	Item no.: 793-5501/000-002 WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type	/000-002	793-5501
	Item no.: 793-5501/000-005 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-005	793-5501
	Item no.: 793-5501/000-006 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-006	793-5501
	Item no.: 793-5501/000-007 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-007	793-5501
	Item no.: 793-5501/000-012 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-012	793-5501
	Item no.: 793-5501/000-017 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-017	793-5501
	Item no.: 793-5501/000-023 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-023	793-5501
	Item no.: 793-5501/000-024 WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type	/000-024	793-5501
Protective Warning Marker			
	Item no.: 280-405 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks		280-405
tools			
	Item no.: 210-720 Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm		210-720
Carrier rail			
	Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25		210-112

	mm	
	Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	210-113
	Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	210-114
	Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	210-115
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-118
	Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	210-196
	Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	210-197
	Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	210-198
	Item no.: 210-504 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	210-504
	Item no.: 210-505 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	210-505
	Item no.: 210-506 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715	210-506
	Item no.: 210-508 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715	210-508

Downloads

Documentation

Bid Text

870-107	doc 25.1 kB	Download
---------	----------------	----------

Additional Information

	pdf 2.1 MB	Download
--	---------------	----------

CAD/CAE - Smart Data

CAD data

3D Download 870-107	URL	Download
---------------------	-----	----------



Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.
