
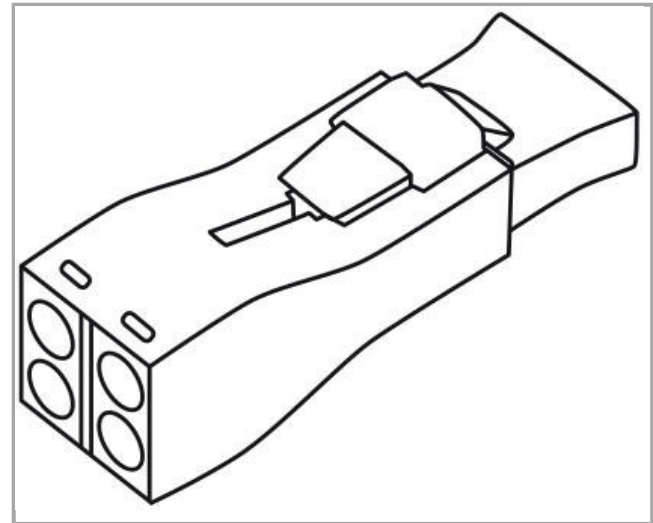


873-902

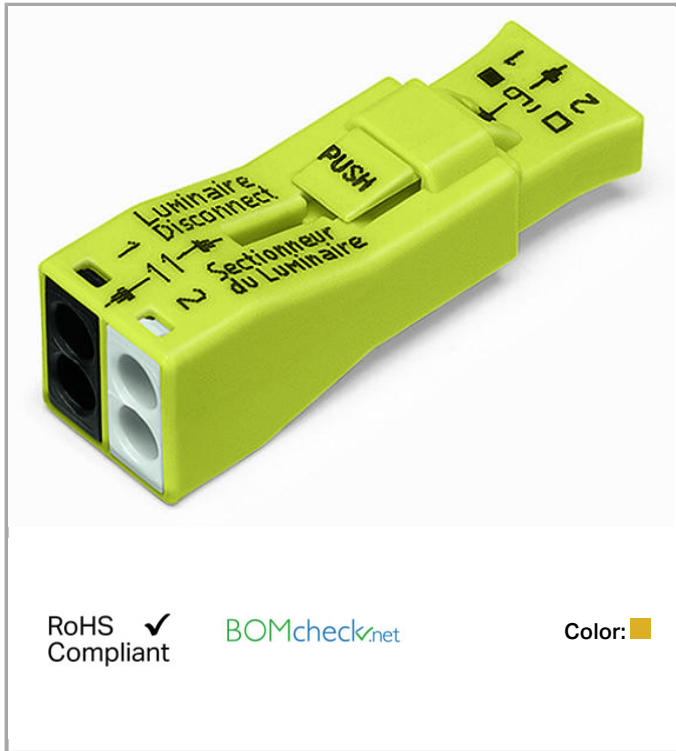

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color: ■

Data

Electrical data

Ratings per IEC/EN 60664-1

Ratings according to 2

EN 61984

Connection data

Connection technology	PUSH WIRE®
Actuation type	Push-in
Connectable conductor materials	Copper
Stranded conductor	1.5 ... 4 mm ² / 16 ... 12 AWG
Strip length	11 ... 13 mm / 0.43 ... 0.51 inch
Solid conductor (2)	1.5 ... 4 mm ² / 16 ... 12 AWG
Strip length (2)	9 ... 11 mm / 0.35 ... 0.43 inch
Solid conductor (3)	0.75 ... 4 mm ² / 18 ... 12 AWG
No. of poles	2
Total number of connection points	4

Total number of potentials	2
----------------------------	---

Geometrical Data

Width	13 mm / 0.512 inch
Height	13.2 mm / 0.52 inch
Depth	42 mm / 1.654 inch

Material Data






Color	yellow
Fire load	0.103 MJ
Weight	4.763 g

Commercial data

Product Group	8 (Misc. Chassis Mount Blocks)
Country of origin	CN
GTIN	4045454548421
Customs Tariff No.	85366990990


Approvals / Certificates

Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 61984	NTR NL-7390
	CCA DEKRA Certification B.V.	EN 61984	2178521.01
	CCA DEKRA Certification B.V.	EN 60998	2178521.02
	CCA DEKRA Certification B.V.	EN 60998	NTR NL-7391
	CSA DEKRA Certification B.V.	C22.2 No. 182.3	154112 (LR 18677)

UL-Approvals



Logo	Approval	Additional Approval Text	Certificate name
	UL UL International Germany GmbH	UL 2459	E313353

Downloads

Documentation

Bid Text

873-902	doc 24.6 kB	Download
---------	----------------	----------

Additional Information

pdf 2.1 MB	Download
---------------	----------

CAD/CAE - Smart Data

CAD data

3D Download 873-902	URL	Download
---------------------	-----	----------

Subject to changes.