



fitted with

work equipment
connected load
power consumption
glare-free
system of protection
class of protection
technology
usage
luminaire body
material
color
weight (net)
mains lead

4 x LED
color temperature 4000K
color rendering index (CRI)=80
electronic transformer
100-240V; 50/60Hz
approx. 33 W
clear prismatic lens
IP20
I
switchable
rocker switch

anodized aluminum
silver
approx. 5.4 kg
approx. 10 ft (3 m) w/ NEMA plug


fastening dimension

screw down lash
4 ft (1256 mm)

illuminance

measuring conditions: d=100cm

E_{min}: 698 lx
E_m: 1139 lx
E_{max}: 1509 lx

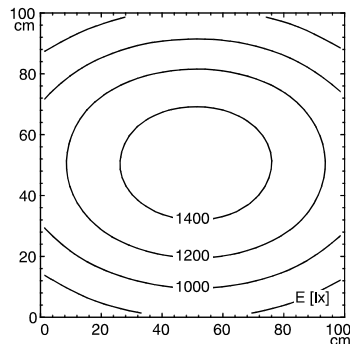

distribution of luminous intensi

