



Mounting bracket
(accessory)

- Robust aluminium housing including wire guard
- Wear-free due to the absence of any moving mechanical components
- Salt water resistant
- Intense rotating signal effect with low power consumption
- AC multi-voltage version
- Robust bracket made of V2A stainless steel (accessory)

Life duration
up to 50,000 hrs

i TECHNICAL SPECIFICATIONS:

Dimensions (Ø x Height):	153 mm x 198 mm
Housing:	Black laquered aluminium with integral wire guard
Lens:	PC, transparent
Fixing:	Base mounting
Connection:	Screw terminal with wire protection max. 2.5 mm ²
Cable entry:	Cable gland M20 x 1.5 mm (included in assembly) Cable diameter 6-13 mm
Installation position:	As required
Rotation rate:	C. 180 r.p.m.

🛒 ORDER SPECIFICATIONS:

Voltage	24 V DC	115-230 V AC
Current consumption	150 mA	70-180 mA
red	839 120 55	839 120 68
yellow	839 320 55	839 320 68



Mounting bracket **975 839 02**




TECHNICAL DIAGRAMS:

see page 317



Generates a high signal effect thanks to the LEDs programmed to create a rotating light

Sizes of Rotating Beacons

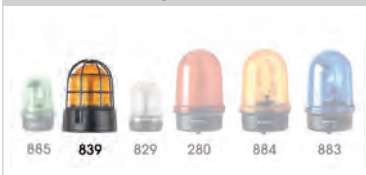

See note on page 347

