




Base mounting



Wall mounting

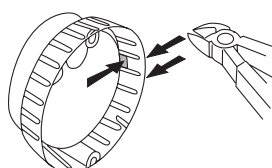

A piece of the rim can be broken out to allow for cable entry from the side



- Buzzer in combination with Xenon Flash
- Optical and audible signal can be triggered separately
- Easy to mount
- Continuous or pulse tone selectable
- Adaptor for tube mounting (accessory)
- Integrated mounting bracket (423)

TECHNICAL SPECIFICATIONS:

| | |
|---------------------------------|---|
| Dimensions (Ø x Height): | 89 mm x 100.5 mm (Base/tube mounting) |
| (L x H x W): | 83 mm x 120.5 mm x 91 mm (Wall mounting) |
| Housing: | Base/tube mounting: PC, black Wall mounting: PC-ABS-Blend; PC grey |
| Lens: | PC, transparent |
| Connection: | Screwable protection with wire protection max. 1.5 mm ² |
| Cable entry: | Cable diameter max. 9 mm |
| Tone type: | Continuous or pulse tone, selectable |
| Tone frequency: | 2.3 kHz |
| Flash energy: | 1 Ws |
| Flash frequency: | 1 Hz |
| Fixing: | Base mounting, tube mounting (accessory), Wall mounting, Sound outlet facing downwards |
| Life duration: | 4 x 10 ⁶ flashes |

ORDER SPECIFICATIONS:

| | | | |
|----------------------------|------------|------------|------------|
| Voltage | 24 V AC/DC | 115 V AC | 230 V AC |
| Current consumption Flash | 120 mA | 25 mA | 35 mA |
| Current consumption Buzzer | 15 mA | 15 mA | 25 mA |
| Base/Tube mounting | | | |
| red | 421 110 75 | 421 110 67 | 421 110 68 |
| yellow | 421 310 75 | 421 310 67 | 421 310 68 |
| Wall mounting | | | |
| red | 423 110 75 | 423 110 67 | 423 110 68 |
| yellow | 423 310 75 | 423 310 67 | 423 310 68 |



ACCESSORIES:

| | |
|--|------------|
| Adaptor for tube mounting, plastic, for tube Ø 25 mm | 975 420 01 |
| Base for tube Ø 25 mm, plastic, incl. rubber seal | 975 840 90 |
| Base for tube Ø 25 mm, metal, incl. rubber seal | 975 840 91 |
| Tube Ø 25 mm, all anodized aluminium | |
| 100 mm | 975 845 10 |
| 250 mm | 975 840 25 |

TECHNICAL DIAGRAMS:

see page 304

See note on page 347

