



- Electronic Horn in combination with LED Permanent Beacon
- Horn with long life duration up to 5,000 hrs
- Optical and audible signal can be triggered separately
- Adjustable sound output (24 V version)

**i TECHNICAL SPECIFICATIONS:**

Life duration up to 50,000 hrs (LED) + 5,000 hrs (Horn)

Dimensions (L x H x W):	83 mm x 234.5 mm x 91 mm
Housing:	PC/ABS-Blend; PC grey
Lens:	PC, transparent
Connection:	Screw terminal with wire protection max. 1.5 mm <sup>2</sup>
Cable entry:	Cable diameter max. 9 mm
Fixing:	Wall mounting, sound outlet facing downwards
Life duration:	50,000 hrs (LED Permanent light) 5,000 hrs (Horn)
Tone frequency:	110 Hz


**🛒 ORDER SPECIFICATIONS:**



Voltage	24 V AC/DC	115 V AC	230 V AC
Current consumption LED	45 mA	25 mA	25 mA
Current consumption Horn	80 mA	70 mA	70 mA
red	<b>424 120 75</b>	<b>424 120 67</b>	<b>424 120 68</b>
yellow	<b>424 320 75</b>	<b>424 320 67</b>	<b>424 320 68</b>

**📐 TECHNICAL DIAGRAMS:**

see page 304

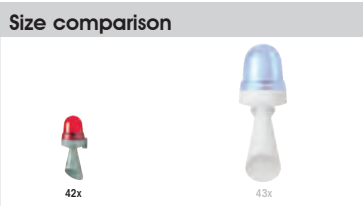

See note on page 347

