



- Electronic Horn in combination with Xenon Flash
- Horn with long life duration of up to 5,000 hrs
- Optical and audible signal can be triggered separately
- Adjustable sound output (24 V version)

i TECHNICAL SPECIFICATIONS:

Dimensions (L x H x W):	83 mm x 234.5 mm x 91 mm
Housing:	PC/ABS-Blend; PC grey
Lens:	PC, transparent
Connection:	Screw terminal with wire protection max. 1.5 mm ²
Cable entry:	Cable diameter max. 9 mm
Flash energy:	1 Ws
Flash frequency:	1 Hz
Fixing:	Wall mounting, sound outlet facing downwards
Life duration:	4 x 10 ⁶ flashes (Xenon Flash) 5,000 hrs (Horn)
Tone frequency:	110 Hz


🛒 ORDER SPECIFICATIONS:

Voltage	24 V AC/DC	115 V AC	230 V AC
Current consumption Flash	120 mA	30 mA	30 mA
Current consumption Horn	80 mA	70 mA	70 mA
red	425 120 75	425 120 67	425 120 68
yellow	425 320 75	425 320 67	425 320 68



📏 TECHNICAL DIAGRAMS:

see page 304

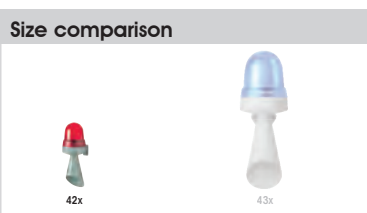

See note on page 347

