



- Gas applications: Zone 1 and 2
- Fully encapsulated
- Silicone free

i TECHNICAL SPECIFICATIONS:




Dimensions (L x H x W):	148 mm x 350 mm x 152 mm
Housing:	PC/ABS-Blend
Connection:	Cable 3 m, 2 x 0.75 mm ²
Fixing:	Bracket mounting, sound outlet facing downwards
Explosion protection	Ex II 2G Ex mb IIC T5 Gb
Approval:	BVS 03 ATEX E 118X

ORDER SPECIFICATIONS:

Voltage	24 V DC	24 V AC	42-48 V AC	115 V AC	230 V AC	
Voltage range	21,6 V ... 26,4 V	21,6 V ... 26,4 V	37,8 V ... 52,8 V	102,5 V ... 126,5 V (50 Hz)	108 V ... 131 V (60 Hz)	208 V ... 250 V (50 Hz)
Current consumpt.	350 mA	450 mA	220 mA	205 mA	70 mA	
	750 000 55	750 000 65	750 000 66	750 000 67	750 000 68	

TECHNICAL DIAGRAMS:

see page 314

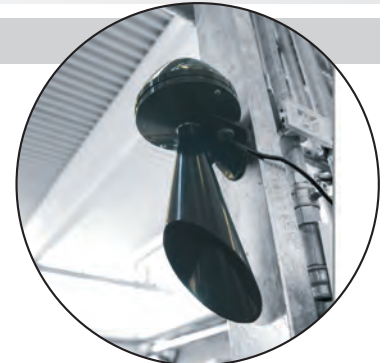

The Ex Signal Horn 750 warns of imminent danger in the chemical industry and paint shops



2 G				
Zone 1 + 2	1,3 kg	IP55	+50°C / -40°C	105 dB