



The colours red, yellow and green can be set via DIP switch for any required order or distribution



Air Cleanliness Class 1

Attention-grabbing illumination in one colour (can be triggered externally)

- LED Signal Tower for use in clean-room applications (Fraunhofer IPA approval) and the food industry (EHEDG approval)
- Permanent light in red, yellow and green (RGY LEDs)
- Colour distribution can be set and adjusted via switch as required
- Complete illumination in one colour possible (can be triggered externally)
- Integrated, high output buzzer (85 dB)

Life duration up to 50.000 hrs

i TECHNICAL SPECIFICATIONS:

Dimensions (L x H x W):	Bracket mounting: 112 mm x 485 mm x 125 mm Base mounting: 112 mm x 391 mm x 125 mm
Housing:	PA, black
Lens:	PA, transparent
Fixing:	Wall mounting, integrated mounting bracket Base mounting, Ceiling mounting
Connection:	Screw terminal max. 1.5 mm ²
Current consumption:	Optical: depending on the colour combination, 240 mA max. Buzzer: 20 mA

🛒 ORDER SPECIFICATIONS:

Voltage	24 V DC
CleanSIGN with Buzzer	
Bracket mounting	695 200 55
Base or Ceiling mounting	695 210 55




⚠️ ADDITIONAL INFORMATION:

Clever solution for wall mounting
A "Pine Tree Clip®" enables quick and simple mounting. The attachment and connection of the tower is carried out from the rear. As a consequence, the housing is completely closed and holes are avoided.

Wide range of sophisticated design features
The CleanSIGN from WERMA is equipped with a series of sophisticated technical, constructional and design features which make a significant contribution to the safety of your products.

For example, the CleanSIGN has no grooves or joints where dirt could collect, facilitating quick and easy cleaning.

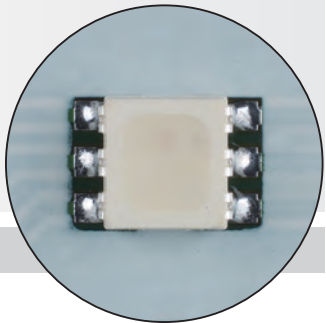

Completely flexible colour distribution thanks to RGY LEDs

📏 TECHNICAL DIAGRAMS:

see page 311

See note on page 347

				695 200 55 	695 210 55 			
--	--	--	--	----------------	----------------	--	--	--