



- LED Permanent beacon with M20 thread for applications such as limit and cable-operated switches
- Extremely high light intensity
- Ideal for installation in limited space due to short thread

Life duration up to 100,000 hrs

i TECHNICAL SPECIFICATIONS:

Dimensions (Ø x Height):	29 mm x 32 mm (Protrusion from panel)
Housing:	PC/ABS-Blend
Lens:	PC, transparent
Connection:	2 wires, c. 115 mm long
Fixing:	Installation mounting for Ø 20.5 mm (M20 x 1.5 mm)

Seal included in assembly.



Mainly sideways illumination

🛒 ORDER SPECIFICATIONS:

Voltage	12 V DC	24 V DC	115 V AC	230 V AC
Current consumption	80 mA	45 mA	15 mA	20 mA
red	230 100 54	230 100 55	230 100 67	230 100 68
yellow	230 300 54	230 300 55	230 300 67	230 300 68
clear	-	230 400 55	-	-

Further colours on request.

📏 TECHNICAL DIAGRAMS:

see page 302

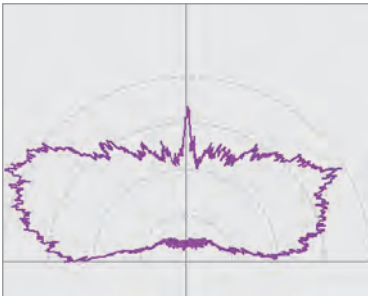


Illustration of the light distribution for the LED Installation Beacon 230



The LED Installation Beacon 230 can for example be used in applications with cable-operated switches or limit switch devices

Sizes of Permanent Beacons



See note on page 347

CE

24 V