

FEATURES-SPECIFICATIONS
Description

Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, freestanding NEMA 4 and freestanding stainless steel enclosures.


- Panels are 10 or 12 gauge steel and can be positioned anywhere along horizontal depth-wise mounting channels
- Half-length panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Panels are painted with a white polyester powder
- Panels may be used in two-door enclosures along with other freestanding accessories
- **Optional "G"** panels have a conductive finish (no paint)

REGULAR PANELS ONLY (FULL & HALF) NEMA 12 SINGLE DOOR

CATALOG NUMBER		STEEL GAUGE	PANEL SIZE A X B	PANEL TYPE
WHITE	"G"			
WA60P24F1	WA60P24F1G	12	48.00x20.00 (1219x508)	Full
WA60P24F2	WA60P24F2G	12	24.88x20.00 (632x508)	Half
WA72P24F1	WA72P24F1G	12	60.00x20.00 (1524x508)	Full
WA72P24F2	WA72P24F2G	12	30.88x20.00 (784x508)	Half
WA90P24F1	WA90P24F1G	12	78.00x20.00 (1981x508)	Full
WA90P24F2	WA90P24F2G	12	39.88x20.00 (1013x508)	Half
WA72P30F1	WA72P30F1G	12	60.00x26.00 (1524x660)	Full
WA72P30F2	WA72P30F2G	12	30.88x26.00 (784x660)	Half
WA60P36F1	WA60P36F1G	12	48.00x32.00 (1219x813)	Full
WA60P36F2	WA60P36F2G	12	24.88x32.00 (632x813)	Half
WA72P36F1	WA72P36F1G	12	60.00x32.00 (1524x813)	Full
WA72P36F2	WA72P36F2G	12	30.88x32.00 (784x813)	Half
WA90P36F1	WA90P36F1G	12	78.00x32.00 (1981x813)	Full
WA90P36F2	WA90P36F2G	12	39.88x32.00 (1013x813)	Half

NOTE: If used in a Two Door Enclosure, a center panel support must be ordered.

NOTE: Suffix F1 = Full Panel, and F2 = Half Panel.

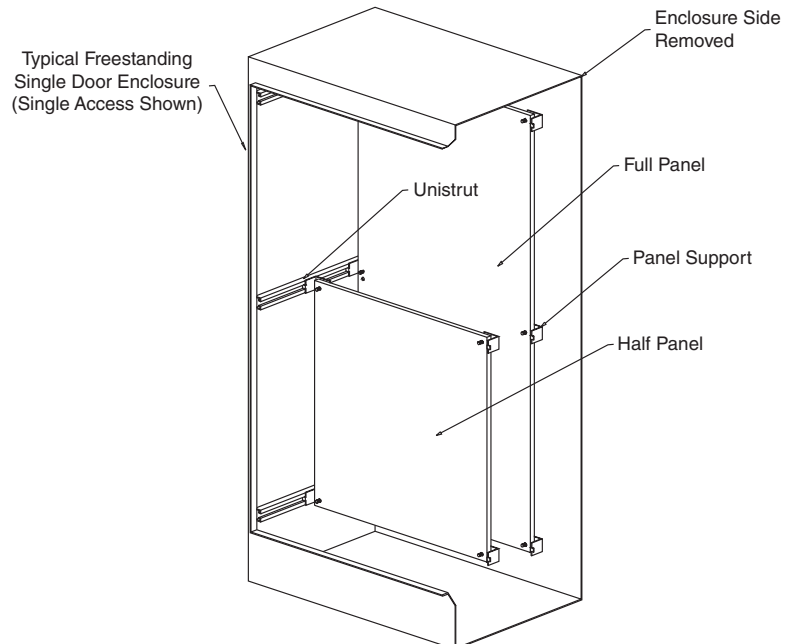

FEATURES-SPECIFICATIONS

Description

Panels for two-door single-access and two-door dual-access Free-standing NEMA 12 enclosures.

- Panels are 10 gauge steel and can be positioned anywhere along horizontal depth-wise mounting channels
- Half-length panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Panels are painted with a white polyester powder
- **Optional "G"** panels have a conductive finish (no paint)

BACK PANELS FOR TWO DOOR FREESTANDING ENCLOSURES				
CATALOG NUMBER		STEEL GAUGE	PANEL SIZE A X B	PANEL TYPE
WHITE	"G"			
WA60P48F1	WA60P48F1G	10	48.00x44.00 (1219x1118)	Full
WA60P48F2	WA60P48F2G	10	24.88x44.00 (632x1118)	Half
WA72P48F1	WA72P48F1G	10	60.00x44.00 (1524x1118)	Full
WA72P48F2	WA72P48F2G	10	30.88x44.00 (784x1118)	Half
WA72P60F1	WA72P60F1G	10	60.00x56.00 (1524x1422)	Full
WA72P60F2	WA72P60F2G	10	30.88x56.00 (784x1422)	Half
WA72P72F1	WA72P72F1G	10	60.00x68.00 (1524x1727)	Full
WA72P72F2	WA72P72F2G	10	30.88x68.00 (784x1727)	Half
WA90P48F1	WA90P48F1G	10	78.00x44.00 (1981x1118)	Full
WA90P48F2	WA90P48F2G	10	39.88x44.00 (1013x1118)	Half
WA90P72F1	WA90P72F1G	10	78.00x68.00 (1981x1727)	Full
WA90P72F2	WA90P72F2G	10	39.88x68.00 (1013x1727)	Half

NOTE: Center Panel support is supplied with a regular Two Door Enclosure Panel. This support is used only as a brace. It is not intended to be used as a support for Single Door Panels, relay racks, etc.
NOTE: Suffix F1 = Full Panel, and F2 = Half Panel.

