


# WADW231302BC

By Wiegmann

Catalog ID: WADW231302BC

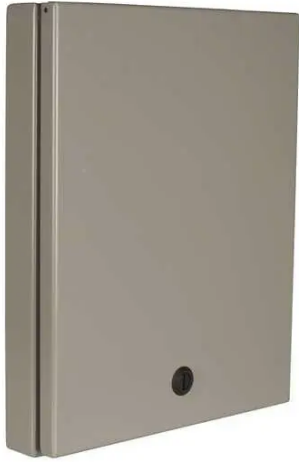

\* Representative image

By Wiegmann

Catalog ID: WADW231302BC

## Prop 65 - Cancer & Reproductive Harm Notice

NEMA 4 Deep Hinged Blank Cover 22.8X13.5X2.8  
Carbon Steel-Gray

The Wiegmann Universal Deep Hinged Door Kit is styled after Wiegmann's N412 Ultimate Series enclosures. Kits are compatible with any NEMA 3R, 4, 4X, and 12 rated enclosures.

- Quarter-turn style latching for wasy access
- Poured in place gasket
- Removable concealed hinge
- Drill template included for ease of mounting and guaranteed alignment

## Product Details

### General

---

Accessory Type	Window/Door Kit
----------------	-----------------

---

Color	Gray
-------	------

---

EU RoHS Indicator	No
-------------------	----

---

Finish Type	Polyester Powder
-------------	------------------

---

Latches Type	Quarter Turn Latch
--------------	--------------------

---

Material	Carbon Steel
----------	--------------

---

Type	Accessory
UPC	786725885459
<b>Dimensions</b>	
Actual Depth	2.75 in
Actual Height	22.75 in
Actual Width	13.5 in
Depth	2 in
Height	23 in
Width	13 in

### **Certifications and Compliance**

Certified Listed	UL Recognized 508A
Nema Rating	4, 12

### **Logistics**

Carton Quantity	1
-----------------	---