


WADW232602BC

By Wiegmann

Catalog ID: WADW232602BC

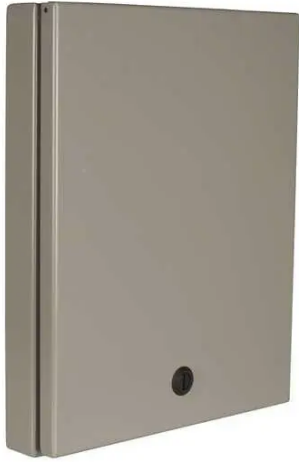

* Representative image

By Wiegmann

Catalog ID: WADW232602BC

Prop 65 - Cancer & Reproductive Harm Notice

NEMA 4 Deep Hinged Blank Cover 22.8X26.3X2.8
Carbon Steel-Gray

The Wiegmann Universal Deep Hinged Door Kit is styled after Wiegmann's N412 Ultimate Series enclosures. Kits are compatible with any NEMA 3R, 4, 4X, and 12 rated enclosures.

- Quarter-turn style latching for wasy access
- Poured in place gasket
- Removable concealed hinge
- Drill template included for ease of mounting and guaranteed alignment

Product Details

General

Accessory Type	Window/Door Kit
Color	Gray
Finish Type	Polyester Powder
Latches Type	Quarter Turn Latch
Material	Carbon Steel
Type	Accessory

Dimensions

Actual Depth 2.75 in

Actual Height 22.75 in

Actual Width 26.25 in

Depth 2 in

Certifications and Compliance

Certified Listed UL Recognized 508A

Nema Rating 4, 12

Logistics

Carton Quantity 1
