


# PCB terminal series 8134 / 8234, rising cage clamp system


pitch 5.00 / 5.08 mm

IEC	250 V 4kV cat.3 690 V 4kV cat.2 1000 V 4kV cat.1	10 A	0.14 - 1.5 mm <sup>2</sup> (Stranded) 0.14 - 2.5 mm <sup>2</sup> (Solid)
UL	300 V	15 A (Field) 16 A (Factory)	30 - 14 AWG
CSA	300 V	15 A	30 - 14 AWG
Solder Pin	0.5 x 1.0 mm		
Drill Hole	1.2 mm		
Wire Strip Length	6.0 mm		
Screw Size	M3		

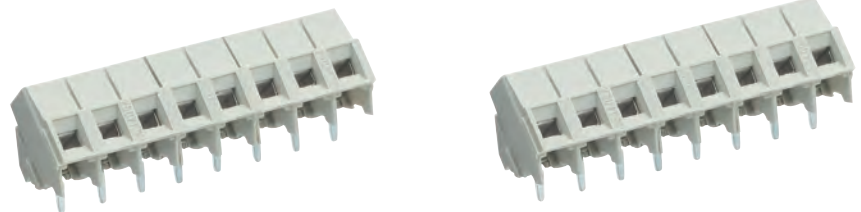

See Technical Data section for screw material options

Approvals:

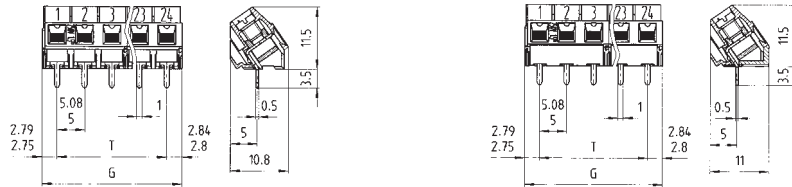

## series 8134 pitch 5.00 mm

Box Qty	G	T	Pole
100	10.55	5	2
100	15.55	10	3
50	20.55	15	4
50	25.55	20	5
50	30.55	25	6
50	35.55	30	7
50	40.55	35	8
50	45.55	40	9
50	50.55	45	10
50	55.55	50	11
50	60.55	55	12
50	65.55	60	13
50	70.55	65	14
50	75.55	70	15
50	80.55	75	16

unmarked without insulating plate

Part Number
25.501.0253.0
25.501.0353.0
25.501.0453.0
25.501.0553.0
25.501.0653.0
25.501.0753.0
25.501.0853.0
25.501.0953.0
25.501.1053.0
25.501.1153.0
25.501.1253.0
25.501.1353.0
25.501.1453.0
25.501.1553.0
25.501.1653.0

marked without insulating plate

Part Number
25.500.0253.0
25.500.0353.0
25.500.0453.0
25.500.0553.0
25.500.0653.0
25.500.0753.0
25.500.0853.0
25.500.0953.0
25.500.1053.0
25.500.1153.0
25.500.1253.0
25.500.1353.0
25.500.1453.0
25.500.1553.0
25.500.1653.0

unmarked with insulating plate with locating cams

Part Number
25.501.6253.0
25.501.6353.0

marked with locating cams

Part Number
25.500.6253.0
25.500.6353.0

## series 8234 pitch 5.08 mm

Box Qty	G	T	Pole
100	10.71	5.08	2
100	15.79	10.16	3
50	20.87	15.24	4
50	25.95	20.32	5
50	31.03	25.40	6
50	36.11	30.48	7
50	41.19	35.56	8
50	46.27	40.64	9
50	51.35	45.72	10
50	56.42	50.80	11
50	61.51	55.88	12
50	66.59	60.96	13
50	71.67	66.04	14
50	76.75	71.12	15
50	81.83	76.20	16

unmarked without insulating plate

Part Number
25.503.0253.0
25.503.0353.0
25.503.0453.0
25.503.0553.0
25.503.0653.0
25.503.0753.0
25.503.0853.0
25.503.0953.0
25.503.1053.0
25.503.1153.0
25.503.1253.0
25.503.1353.0
25.503.1453.0
25.503.1553.0
25.503.1653.0

marked without insulating plate

Part Number
25.502.0253.0
25.502.0353.0
25.502.0453.0
25.502.0553.0
25.502.0653.0
25.502.0753.0
25.502.0853.0
25.502.0953.0
25.502.1053.0
25.502.1153.0
25.502.1253.0
25.502.1353.0
25.502.1453.0
25.502.1553.0
25.502.1653.0

unmarked with insulating plate with locating cams

Part Number
25.503.6253.0
25.503.6353.0

marked with locating cams

Part Number
25.502.6253.0
25.502.6353.0