

Pluggable PCB terminals series 8513 / 8813, rising cage clamp system

pitch 3.50 / 3.81 mm





IEC	125 V 2.5kV cat.3 250 V 2.5kV cat.2 690 V 2.5kV cat.1	8 A	0.14 - 1.5 mm ² (Stranded) 0.14 - 1.5 mm ² (Solid)
UL	300 V	8 A	30 - 16 AWG
CSA	300 V	5 A	22 - 14 AWG



Wire Strip Length 6.5 mm
Screw Size M2

See Technical Data section for screw material options

Approvals:

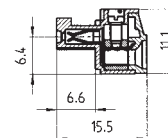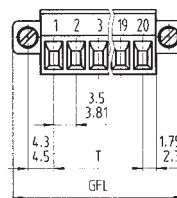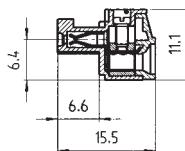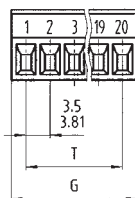

series 8513 B pitch 3.50 mm

Box Qty	G	T	Pole
100	7.00	3.50	2
100	10.50	7.00	3
50	14.00	10.50	4
50	17.50	14.00	5
50	21.00	17.50	6
50	24.50	21.00	7
50	28.00	24.50	8
50	31.50	28.00	9
50	35.00	31.50	10
50	38.50	35.00	11
50	42.00	38.50	12
50	45.50	42.00	13
50	49.00	45.50	14
50	52.50	49.00	15
50	56.00	52.50	16

unmarked	marked	unmarked with screw flange	unmarked with screw flange
Part Number	Part Number	Part Number	Part Number
25.640.3253.0	25.640.0253.0	25.641.3253.0	25.641.0253.0
25.640.3353.0	25.640.0353.0	25.641.3353.0	25.641.0353.0
25.640.3453.0	25.640.0453.0	25.641.3453.0	25.641.0453.0
25.640.3553.0	25.640.0553.0	25.641.3553.0	25.641.0553.0
25.640.3653.0	25.640.0653.0	25.641.3653.0	25.641.0653.0
25.640.3753.0	25.640.0753.0	25.641.3753.0	25.641.0753.0
25.640.3853.0	25.640.0853.0	25.641.3853.0	25.641.0853.0
25.640.3953.0	25.640.0953.0	25.641.3953.0	25.641.0953.0
25.640.4053.0	25.640.1053.0	25.641.4053.0	25.641.1053.0
25.640.4153.0	25.640.1153.0	25.641.4153.0	25.641.1153.0
25.640.4253.0	25.640.1253.0	25.641.4253.0	25.641.1253.0
25.640.4353.0	25.640.1353.0	25.641.4353.0	25.641.1353.0
25.640.4453.0	25.640.1453.0	25.641.4453.0	25.641.1453.0
25.640.4553.0	25.640.1553.0	25.641.4553.0	25.641.1553.0
25.640.4653.0	25.640.1653.0	25.641.4653.0	25.641.1653.0

series 8813 B pitch 3.81 mm

Box Qty	G	T	Pole
100	8.41	3.81	2
100	12.22	7.62	3
50	16.03	11.43	4
50	19.84	15.24	5
50	23.65	19.05	6
50	27.46	22.86	7
50	31.27	26.67	8
50	35.08	30.48	9
50	38.89	34.29	10
50	42.70	38.10	11
50	46.51	41.91	12
50	50.32	45.72	13
50	54.13	49.53	14
50	57.94	53.34	15
50	61.75	57.15	16

unmarked	marked	unmarked with screw flange	unmarked with screw flange
Part Number	Part Number	Part Number	Part Number
25.620.3253.0	25.620.0253.0	25.621.3253.0	25.621.0253.0
25.620.3353.0	25.620.0353.0	25.621.3353.0	25.621.0353.0
25.620.3453.0	25.620.0453.0	25.621.3453.0	25.621.0453.0
25.620.3553.0	25.620.0553.0	25.621.3553.0	25.621.0553.0
25.620.3653.0	25.620.0653.0	25.621.3653.0	25.621.0653.0
25.620.3753.0	25.620.0753.0	25.621.3753.0	25.621.0753.0
25.620.3853.0	25.620.0853.0	25.621.3853.0	25.621.0853.0
25.620.3953.0	25.620.0953.0	25.621.3953.0	25.621.0953.0
25.620.4053.0	25.620.1053.0	25.621.4053.0	25.621.1053.0
25.620.4153.0	25.620.1153.0	25.621.4153.0	25.621.1153.0
25.620.4253.0	25.620.1253.0	25.621.4253.0	25.621.1253.0
25.620.4353.0	25.620.1353.0	25.621.4353.0	25.621.1353.0
25.620.4453.0	25.620.1453.0	25.621.4453.0	25.621.1453.0
25.620.4553.0	25.620.1553.0	25.621.4553.0	25.621.1553.0
25.620.4653.0	25.620.1653.0	25.621.4653.0	25.621.1653.0

Custom Marking Available
More poles available on request