

ST 18/3poles Male parts

coding


black/white

green




double screw connector

strain relief for one round cable
diameter 6.5–8.3 mm

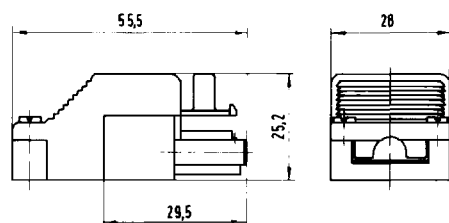


double screw connector

strain relief for two round cables
diameter 4.5–10.0 mm
or one flat cable

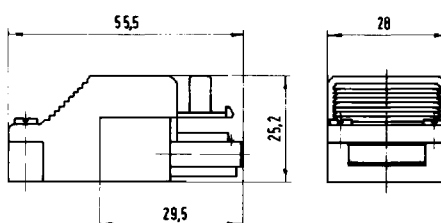

double screw connector

strain relief for one round cable
diameter 6.5–8.3 mm

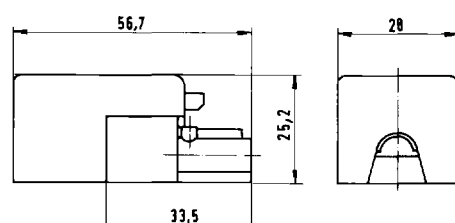


color ref. no. POF



male part assembled
with strain relief without locking device

black **93.732.6353.0** 100
white **93.732.6350.0** 100


color ref. no. POF

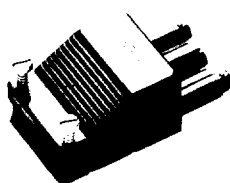

male part assembled
with strain relief without locking device

black **93.632.6353.0** 100
white **93.632.6350.0** 100

color ref. no. POF

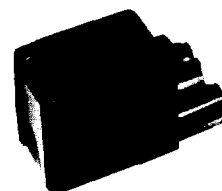

female part assembled
with strain relief without locking device

black **93.733.3353.0** 100
white **93.733.3350.0** 100

male part assembled
with strain relief with locking device

black **93.732.7353.0** 100
white **93.732.7350.0** 100

male part assembled
with strain relief with locking device

black **93.632.7353.0** 100
white **93.632.7350.0** 100

female part assembled
with strain relief with locking device

black **93.733.4353.0** 100
white **93.733.4350.0** 100

male part unassembled
with strain relief without locking device

black **93.932.6353.0** 200
white **93.932.6350.0** 200

male part unassembled
with strain relief without locking device

black **93.832.6353.0** 200
white **93.832.6350.0** 200

female part unassembled
with strain relief without locking device

black **93.933.3353.0** 200
white **93.933.3350.0** 200

male part unassembled
with strain relief with locking device


black **93.932.7353.0** 200
white **93.932.7350.0** 200

male part unassembled
with strain relief with locking device

black **93.832.7353.0** 200
white **93.832.7350.0** 200


female part unassembled
with strain relief with locking device

black **93.933.4353.0** 200
white **93.933.4350.0** 200

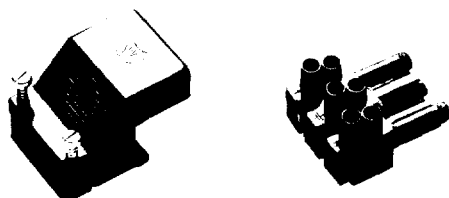


male part

black **93.032.6353.0** 200
white **93.032.6350.0** 200

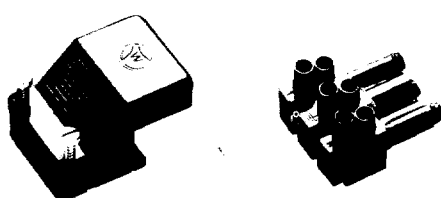

male part

black **93.032.6353.0** 200
white **93.032.6350.0** 200

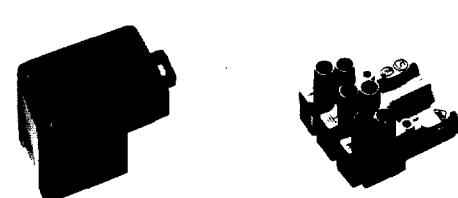

female part

black **93.031.3353.0** 200
white **93.031.3350.0** 200

strain relief complete with top and bottom part
without locking device

black **27.410.8253.0** 200
white **27.410.8250.0** 200

strain relief complete with top and bottom part
without locking device

black **27.410.5253.0** 200
white **27.410.5250.0** 200

strain relief complete with top and bottom part
without locking device

black **27.419.2453.0** 200
white **27.419.2453.2** 200

strain relief complete with top and bottom part
with locking device

black **27.410.3453.0** 200
white **27.410.3450.0** 200

strain relief complete with top and bottom part
with locking device

black **27.410.3353.0** 200
white **27.410.3350.0** 200

strain relief complete with top and bottom part
with locking device

black **27.419.2253.0** 200
white **27.419.2253.2** 200