

## Datasheet

Art.No. 82.003.0110.0

### Analogue Isolation Amplifier cores C1 UI-B

cores C1 UI-B, analog converter, 3-way electrical isolation 1.5kV; input signal: 0/1...5V DC or 0/2...10V DC, 0/4...20mA DC; output signal: 0/1...5V DC or 0/2...10V DC, 0/4...20mA DC or 20...4/0mA DC; accuracy 0.1%; supply voltage 24V AC/DC; W x H x D: 6.2 × 93.1 × 102.5 mm



Art.No.	82.003.0110.0
EAN	4049088152863
Order unit	1 pieces

## Approvals

## Technical data

### Technical data


Input range (adjustable)	0/1 ... 5 V DC oder 0/2 ... 10 V DC, 0/4 ... 20 mA DC
Output range (adjustable)	0/1 ... 5 V DC or 0/2 ... 10 V DC, 0/4 ... 20 mA DC or 20 ... 4/0 mA DC activ or passiv
Galvanic isolation	yes, 3 way isolation
Isolation voltage	1500 V
Accuracy	
Input voltage DC min.	19.2 V
Input voltage DC max.	30 V
Power consumption	0.5 W
Connection type	Tension clamp connection
Wire range solid/fine-stranded	0,2 - 2,5 mm <sup>2</sup>
Operating temperature min.	-20 °C
Operating temperature max.	65 °C

### Dimensions

Depth	102.5 mm
Width	6.2 mm
Height	93.1 mm



Drawings

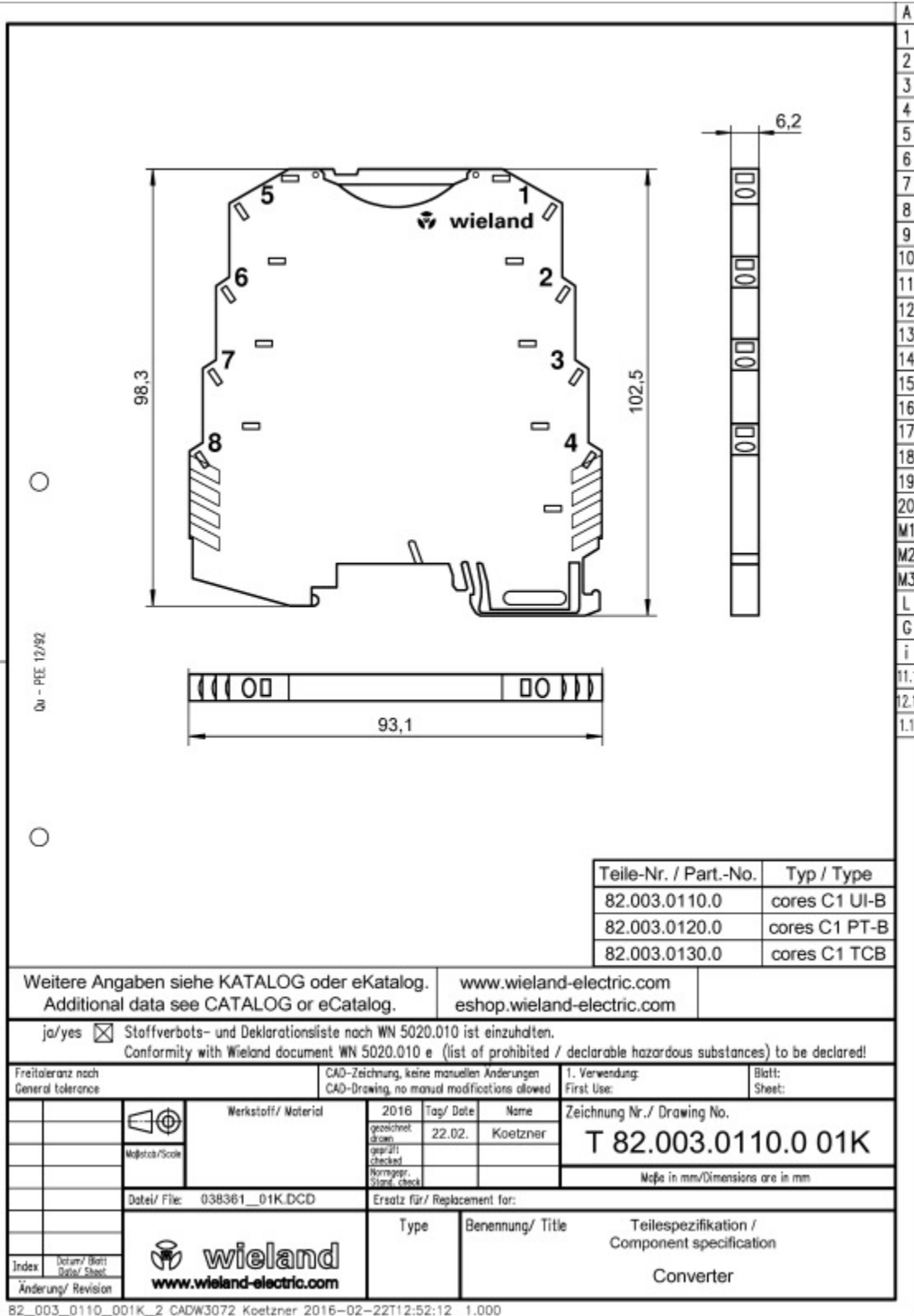

B2\_003\_0110\_001K\_2 CADW3072 Koetzner 2016-02-22T12:52:12 1.000