


Data sheet

Commercial Art.No.: Z1.299.4255.0

fuse holder SIST- GL /V0

Fuse holder to stick on disconnect base block type WK 4 TKG..., with LED- indicator 220 V, for fuse 5x20mm, color: blue

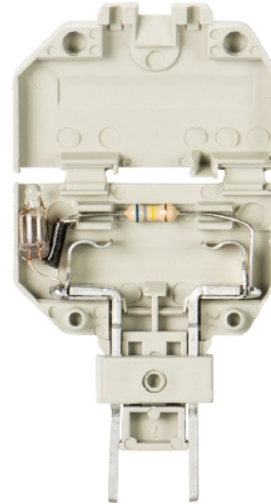

Commercial Art.No.	Z1.299.4255.0
EAN	4015573528284
Order Unit	10

certificates / approvals



Technical data

general

color	grey
width/grid dimension	6 mm
insulating housing	PA666
flammability class of insulation material acc. with UL94	V0
mounting method	direct mounting
fuse insert	G-fuse 5x20 mm
Montageart	direct mounting
Brennbarkeitsklasse des Isolierstoffs	V0

technical data

rated voltage	250 V
closing plate required	no
type of insulation material	thermoplastic
length	32.5 mm

additional data

remark to rated voltage	note fuse insert
remark to rated current	note fuse insert
defect indicator	glow lamp
voltage type for defect indication	AC/DC
minimum operating voltage of defective display	110 V

maximum operating voltage of defective display	250 V
--	-------

classification

ECLASS 11	
ECLASS 8.1	27141116
ETIM 9.0	EC000899
ETIM 8.0	EC000899
ETIM 7.0	EC000899
ETIM 6.0	EC000899
ETIM 5.0	EC000899
ETIM 4.0	EC000899
ETIM 3.0	EC000899

product compliance

ROHS conformity status	compliant/exempted
ROHS exceptions	III-6(c)
REACH-SVHC conformity status	compliant

Accessories

Commercial Art.No.:	Article-type description:	Description:

These dimensions will be especially checked at delivery
 Only inspection dimensions
 With /E marked dimensions are only valid for internal use

Diese Maße werden bei Abnahme besonders geprüft
 Ausschließlich Prüfmaße
 Mit /E gekennzeichnete Maße sind nur für interne Zwecke gültig

These dimensions will be especially checked at delivery
 Only inspection dimensions
 With /E marked dimensions are only valid for internal use

These dimensions will be especially checked at delivery
 Only inspection dimensions
 With /E marked dimensions are only valid for internal use

mit Kennmelder
 with indicator

Do not disconnect under load.
 Ne debrancher pas sous charge.

Selbstklebeschild
 je Verpackungseinheit beigelegt
 Adhesive label added per
 packing unit

= spezielle Verpackung/special package

Teile-Nr. Part-no.	Typ type	Glimmlampe glow lamp	LED	Farbe colour
Z1.299.4055.0 für Sicherung/for fuse 5x20	SIST /VO			grau/grey
Z1.299.4155.0 24V	SIST- LED/VO		X	grau/grey
Z1.299.4155.6 24V	SIST- LED/VO BL		X	blau/blue
Z1.299.4255.0 220V	SIST- GL /VO	X		grau/grey
Z1.299.4255.5 220V	SIST- GL /VO RT	X		rot/red
# Z1.299.4095.0 für Sicherung/for fuse 5x20	SIST /VO			kieselgrau/pebble grey
# Z1.299.4195.0 24V	SIST- LED/VO		X	kieselgrau/pebble grey
# Z1.299.4295.0 220V	SIST- GL /VO	X		kieselgrau/pebble grey

Tolerierung nach DIN 7167/Tolerance system acc. to DIN 7167.
 (This DIN-standard describes the envelope principle. According to the envelope principle the deviations of form and parallelism are limited by the size tolerances).

ja/yes Stoffverbots- und Deklarationsliste nach UU-TQM-05/03 ist einzuhalten.
 Conformity with Wieland document UU-TQM-05/03 (list of prohibited / declarable hazardous substances) to be declared!


Freitoleranz nach
 General tolerance

CAD - Zeichnung, keine manuellen Änderungen
 CAD - drawing, no manual modifications allowed

1.Verwendung:
 First Use:

Blatt: 1 von 1
 Sheet: 1 of 1

	/		Werkstoff/Material	2005	Tag/Date	Name	Zeichnung Nr./Drawing No.	Index
	/			gezeichnet drawn	08.04.	Schmitt J.	T Z1.299.4055.0 01K a	a
	/	Maßstab/Scale		geprüft checked	-	-		
	/	2:1		Normgepr. Stand. check	-	-		
	/	Vol.	mm ³ Of1./Surf.	mm ²	Ersatz für/Replacement for: -			Maße in mm/Dimensions are in mm
	/		wieland	Type	Benennung/Titel FUSE HOLDER SICHERUNGSHALTER			
a	05.11.2009/							
Index	Datum / Blatt Date / Sheet							
Änderung/Revision			Elektrische Verbindungen					

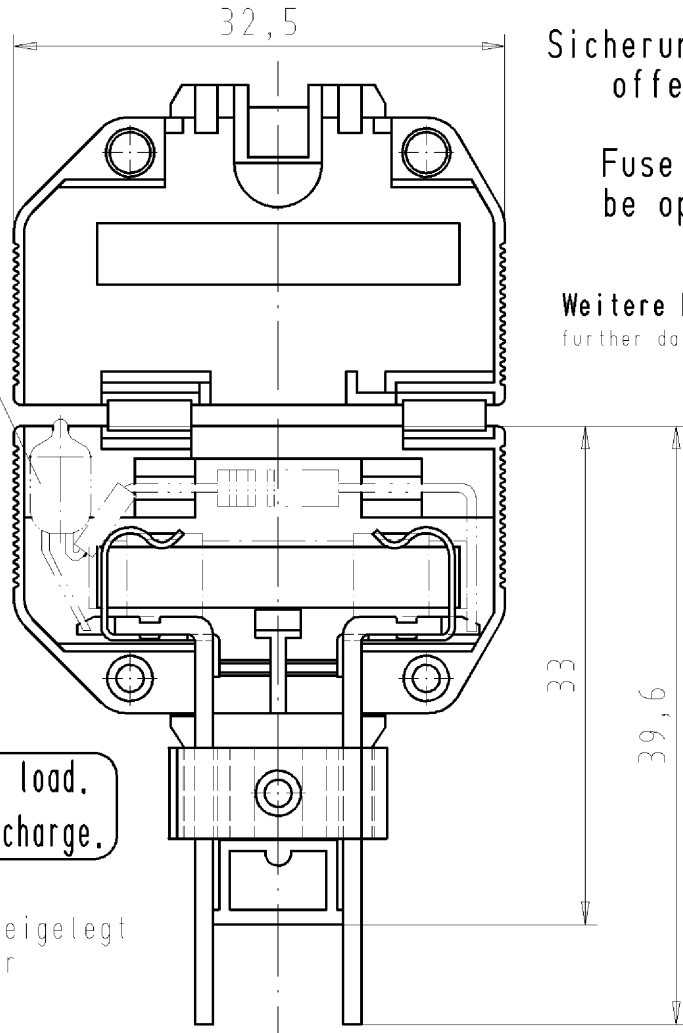

Sicherungshalter wird
 offen geliefert
 Fuse holder will
 be open supplied
 Weitere Daten siehe Katalog
 further data see catalog

Weitergabe sowie Vervielfältigung dieses Dokuments, Verwertung und Mitteilung seines Inhalts sind verboten, soweit ausdrücklich gestattet.
 The reproduction, distribution and utilization of this document as well as communication of its contents to others without express authorization is prohibited.