


Data sheet

Commercial Art.No.: 91.020.7253.0

distributor GST15I2V 2P1H W BL02

gesis® MINI h-distributor, with fastening option to 07.418.9153.1, number of poles 2, rated voltage 50 V, rated current 16 A, number of inputs 1, number of outputs 2, color of coding/ contact carrier light blue

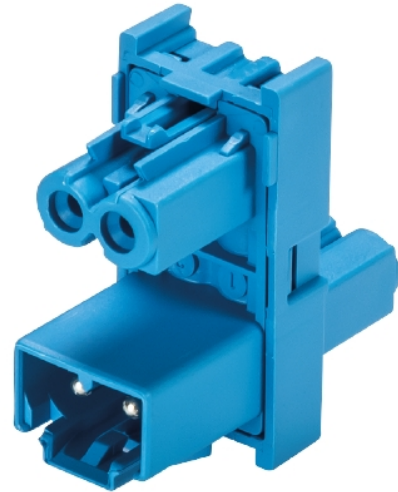

certificates / approvals



Technical data

general

rated current	16 A
rated voltage	50 V
rated impulse voltage	4 kV
pollution degree	2
mechanical coding	code 3
lockable	self-locking (unlocking by tool)
color of coding/ contact carrier	light blue
Pole codification	1, 2
RAL number coding/contact insert	5012

model

number of inputs	1
number of outputs	2
type of fastening	yes
degree of protection (IP)	IP20
type of distributor	h-distributor

material

housing material	polyamide
halogen free	yes
contact material	CuZn
fire load	0.046 kWh/St
surface finish	silver-plated

classification

ECLASS 11	
-----------	--

ECLASS 8.1	27440603
ETIM 9.0	EC002567
ETIM 8.0	EC002567
ETIM 7.0	EC002567
ETIM 6.0	EC002567
ETIM 5.0	EC002567
ETIM 4.0	EC002567

product compliance

ROHS conformity status	compliant/exempted
ROHS exceptions	III-6(c)
REACH-SVHC conformity status	Duty-To-Declare
REACH-SVHC substances	Lead
REACH-SVHC CAS numbers	7439-92-1