


Datasheet

Item No. 70.342.0635.1

Bottom BAS GUT GT 6 M20 50 A1

revos BASIC 500V size 6 closed-bottom base with threaded collar M20, right, with cover, single locking lever

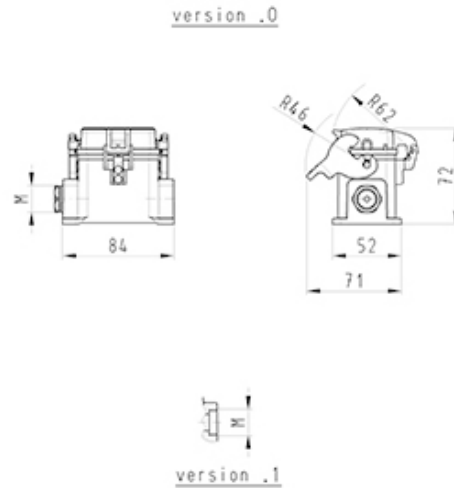

| | |
|------------|---------------|
| Item No. | 70.342.0635.1 |
| EAN | 4015573618169 |
| order unit | 1 Piece(s) |

Approvals



Technical data

General

| | |
|--|---------------------|
| ArticlePrice | udp_no_price |
| Nominal voltage | 500 |
| Housing material | Aluminium |
| Colour | Grey |
| Surface | With powder coating |
| Degree of protection (IP) | Other |
| UV resistant | Yes |
| Inflammability class of insulation material acc. with UL94 | Other |
| Operating temperature range min. | -40 °C |
| Operating temperature range max. | 120 °C |

Model

| | |
|------------------------|-------------------------|
| DIN-size | 6 |
| Model | Surface mounting (base) |
| Locking mechanism | Single locking lever |
| Cable entry | Sideways |
| Type of cable | Thread |
| With cable screw gland | No |
| Thread size M | 20 |
| Hinged lid | Yes |
| EMC-version | No |

Drawings