



Datasheet

Item No. 70.350.1035.2

Hood BAS GOT GA 10 M20 50 A2

revos BASIC 500V size 10 hood with intermediate support M20, lateral cable entry, double locking lever

version .0

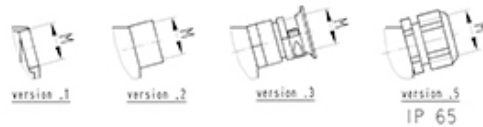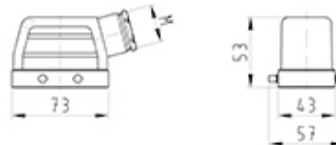

Item No.	70.350.1035.2
EAN	4015573598485
order unit	1 Piece(s)

Approvals



Technical data

General

ArticlePrice	udp_no_price
Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	10
Model	male
Locking mechanism	Double locking levers
Cable entry	Sideways
Type of cable	Intermediate support
With cable screw gland	No
Thread size M	20
Hinged lid	No
EMC-version	No

Drawings