



**Datasheet**

Item No. 70.353.1035.1

**Hood BAS GOT GA 10 M25 50 A1**

revos BASIC 500V size 10 hood with threaded collar M25, lateral cable entry, double locking lever

version .0

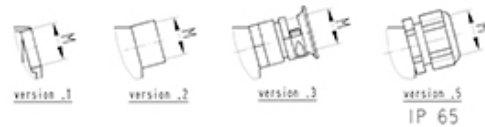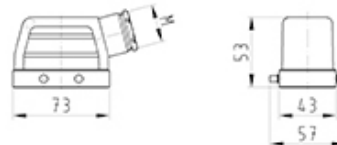

Item No.	70.353.1035.1
EAN	4015573648067
order unit	1 Piece(s)

**Approvals**

**Technical data**
**General**

ArticlePrice	udp_no_price
Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

**Model**

DIN-size	10
Model	male
Locking mechanism	Double locking levers
Cable entry	Sideways
Type of cable	Thread
With cable screw gland	No
Thread size M	25
Hinged lid	No
EMC-version	No

Drawings