


Datasheet

Item No. 71.341.2435.0

Bottom BAS GUT GS 24 M25 50 A0

revos BASIC 500V size 24 closed-bottom base with cable gland M25, left, with cover, single locking lever

version .0

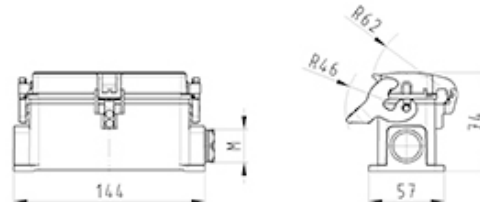

version .1



Item No.	71.341.2435.0
EAN	4015573624931
order unit	1 Piece(s)

Approvals



Technical data

General

ArticlePrice	udp_no_price
Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Surface mounting (base)
Locking mechanism	Single locking lever
Cable entry	Sideways
Type of cable	Gland nut
With cable screw gland	Yes
Thread size M	25
Hinged lid	Yes
EMC-version	No