


Datasheet

Item No. 71.374.2435.0

Hood BAS GOT GL 24 M32 50 A0

revos BASIC 500V size 24 hood for cable-to-cable couplings with cable gland M32, top cable entry, single locking lever

version .0

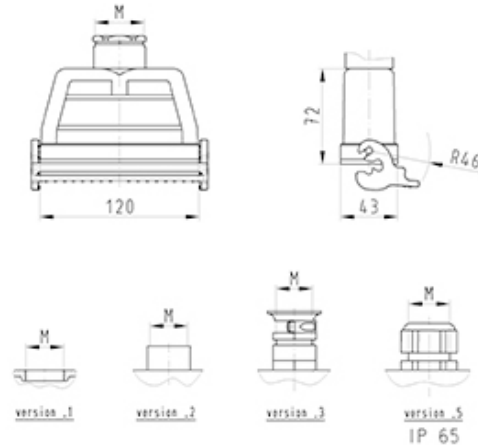

Item No.	71.374.2435.0
EAN	4015573671775
order unit	1 Piece(s)

Approvals



Technical data

General

ArticlePrice	udp_no_price
Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Cable coupler
Locking mechanism	Single locking lever
Cable entry	Above
Type of cable	Gland nut
With cable screw gland	Yes
Thread size M	32
Hinged lid	No
EMC-version	No