


## Datasheet

Item No. 76.353.6435.1

Hood BAS GOT GG 64HM32 50 A1

revos BASIC 500V size 24H hood with threaded collar M32, lateral cable entry, high design, single locking lever

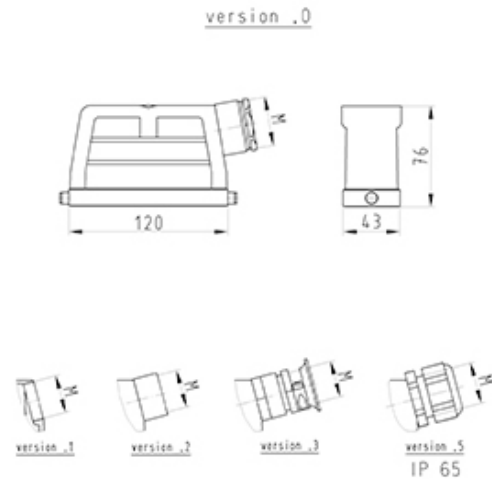

Item No.	76.353.6435.1
EAN	4015573629509
order unit	1 Piece(s)

## Approvals



## Technical data

### General

ArticlePrice	udp_no_price
Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

### Model

DIN-size	24H
Model	male
Locking mechanism	Single locking lever
Cable entry	Sideways
Type of cable	Thread
With cable screw gland	No
Thread size M	32
Hinged lid	No
EMC-version	No

Drawings